

Gage Selector 3

3-channel Switching Box for Data Transmission

FEATURES

- Three digimatic gages can be connected.
- You can specify the gage which outputs the data with the channel switch.


SPECIFICATIONS

Order No.	Description
939039	Gage Selector 3



939039

Examples of Connections

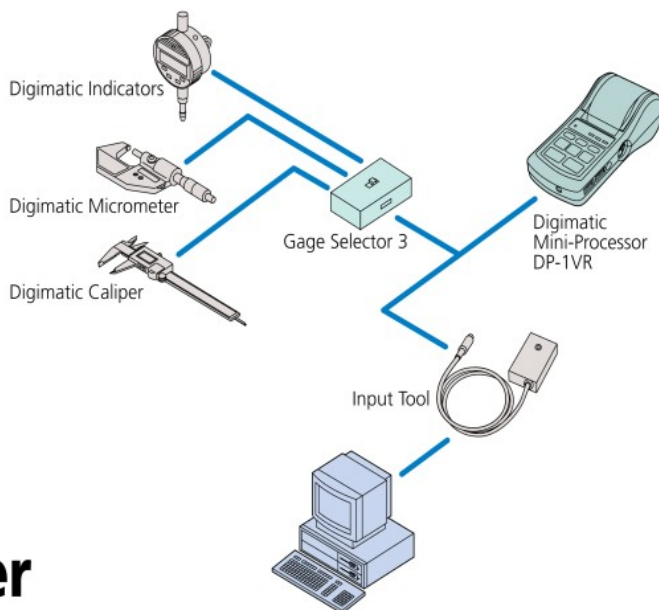

EC Counter

SERIES 542 — Assembly-type Display Unit

FEATURES

- Compact panel mounting type and DIN size. It can be easily incorporated into each system.


SPECIFICATIONS

Order No.	Description
542-007A	EC Counter



542-007A

DIMENSIONS

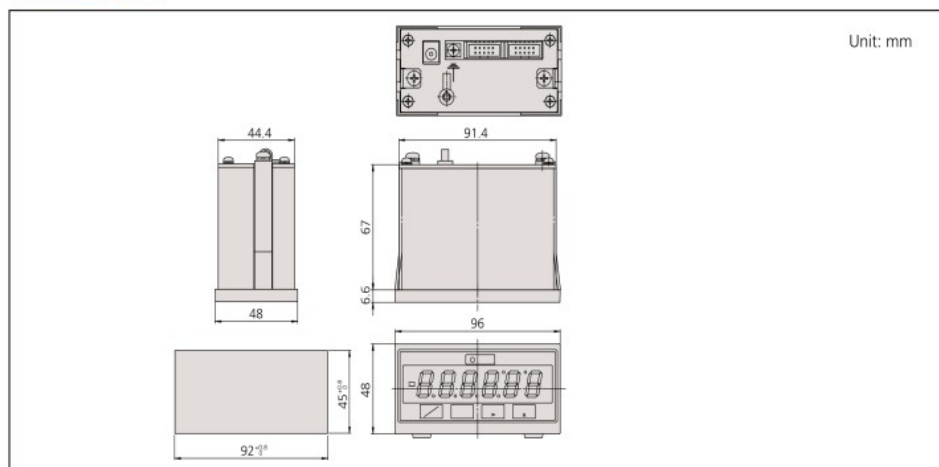

Technical Data

Connection: Up to three gages
 Signal: Digimatic code format
 Connection: Bidirectional
 External dimensions (W x D x H): 100 x 70 x 33mm

Technical Data

Applicable gage: LGD, LGS, All SPC output gages
 Resolution: .0005"/.0001"/0.001mm,
 .0005"/.001"/0.01mm
 No. of gage input: 1
 Display: 6-digit LED and a negative [-] sign
 Function: Preset
 Go-no-go judgment
 Output (open-collector): 3-step limit signal, Normal signal
 External control: Preset, Data hold
 Power supply: Via AC adaptor
 Dimensions (W x D x H): 96 x 48 x 84.6mm
 Mass: 50g

Standard Accessory

06AEG302JA: AC Adapter