


Optional Accessories

- 12AAF712:** Battery pack
- 12AAA797** Thermal printer (120V)
- 12AAA802** Thermal printing paper (10pcs.)
- 12AAA804** Cable for page printer** (2m)
- 12AAA807** RS-232C cable (80" / 2m)
- 12AAA808** RS-232C cable (160" / 4m)

 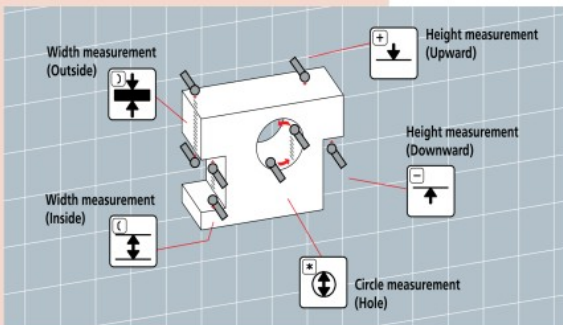


Optional probes and calibration blocks


12AAF666
ø1 ball probe




12AAF670
ø5 disk probe




12AAC072 Depth probe

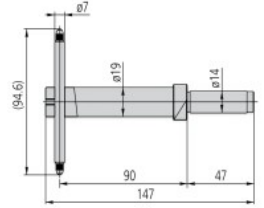


957261
ø2 ball probe

 


12AAF671
ø10 disk probe

 


12AAC073 ø20 taper probe

 


12AAF667
ø2 ruby ball probe

 


957264
ø14 disk probe

 


957262
ø3 ball probe

 

957265
ø20 disk probe

 

957263
ø4 ball probe

 


12AAF672
ø1 ball offset probe*
*test indicator stylus (103017)




12AAA792 Dial indicator (ø8 stem) holder


12AAA837 Dial indicator (ø3/8" stem) holder

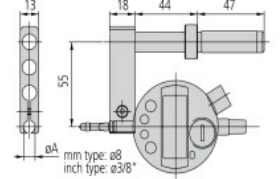


12AAB552
ø10 ball probe, L=55

 


12AAF673
ø2 ball offset probe

 


12AAF668
ø10 ball probe, L=82

 


12AAA788
ø4 ball offset probe

 

12AAF669
ø10 ball probe, L=120

 


12AAA789
ø6 ball offset probe

 


932361 Mu-checker lever head holder
CMM ball and disk hard probes are available.

 226117
M2 CMM stylus adapter




12AAA787 Block for calibrating probe diameter
(applicable to taper probe)

 226118
M3 CMM stylus adapter




K650986 Styli Kit M3

12AAA793 Probe extension holder (85mm/3.3")

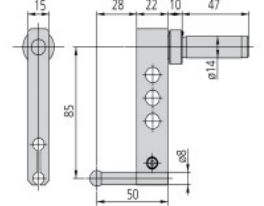

12AAB136 ø10 cylindrical probe

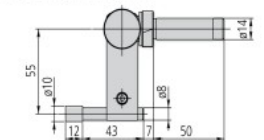

DIMENSIONS AND MASS

