


## 外形寸法図

(mm)

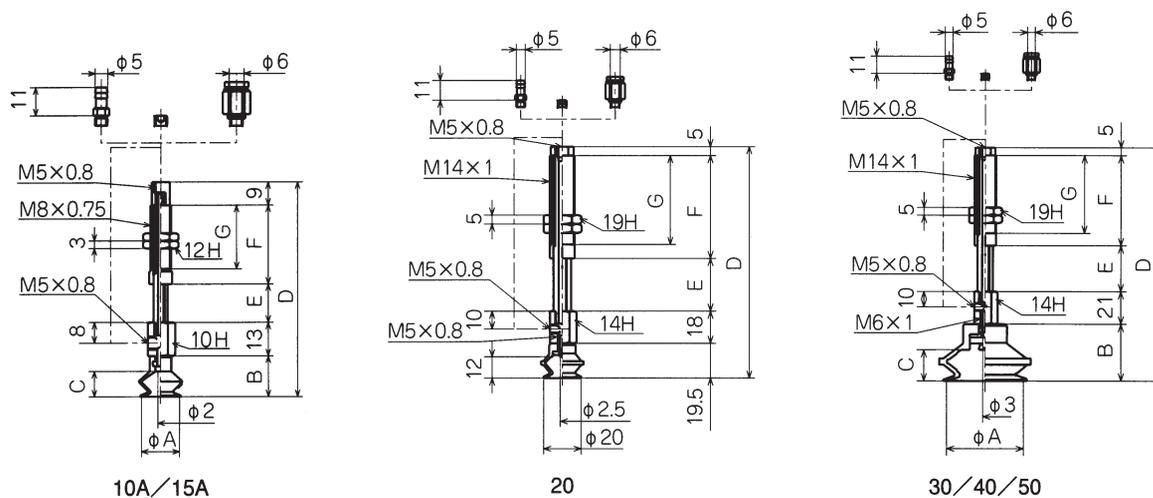

NAPBT/YH	A	B	C	D	E	F	G	F <sup>1</sup>	F <sup>2</sup>	質量 (g)
NAPBT/YH-10A-3	10	13.5	7.5	61.5	3	23	17	0.61	0.77	18.5
NAPBT/YH-10A-10	10	13.5	7.5	68.5	10	23	17	0.61	1.17	19
NAPBT/YH-10A-15	10	13.5	7.5	81	15	30.5	24.5	0.64	1.17	22
NAPBT/YH-15A-3	15	16	10	64	3	23	17	0.61	0.77	18.5
NAPBT/YH-15A-10	15	16	10	71	10	23	17	0.61	1.17	19
NAPBT/YH-15A-15	15	16	10	83.5	15	30.5	24.5	0.64	1.17	22
NAPBT/YH-20-6				84.5	6	36	28	2.45	3.43	63.5
NAPBT/YH-20-15				93.5	15	36	28	2.45	4.9	68.5
NAPBT/YH-20-30				130.5	30	58	50	2.9	5.88	92.5
NAPBT/YH-30-6	30	30.5	17	98.5	6	36	28	2.45	3.43	70.5
NAPBT/YH-30-15	30	30.5	17	107.5	15	36	28	2.45	4.9	75.5
NAPBT/YH-30-30	30	30.5	17	144.5	30	58	50	2.9	5.88	99.5
NAPBT/YH-40-6	40	30.5	15.5	98.5	6	36	28	2.45	3.43	76.5
NAPBT/YH-40-15	40	30.5	15.5	107.5	15	36	28	2.45	4.9	81.5
NAPBT/YH-40-30	40	30.5	15.5	144.5	30	58	50	2.9	5.88	105.5
NAPBT/YH-50-6	50	36.5	20	104.5	6	36	28	2.45	3.43	95
NAPBT/YH-50-15	50	36.5	20	113.5	15	36	28	2.45	4.9	100
NAPBT/YH-50-30	50	36.5	20	150.5	30	58	50	2.9	5.88	124

注意. 表中記号F<sup>1</sup>は0ストローク時、F<sup>2</sup>はフルストローク時のバネ荷重 (N) を表します。