

RoHS Compliant

ERON®

 
 

No.E-425

Spherical Flanged Nuts

Material S45C **Heat Treatment** HRC30 ± 5 heat treatment

Surface Treatment Blackened


- Provides consistently stable clamping without affecting the parallelism of the workpiece, bolt, etc.
- Comes as a set with self-aligning washers.

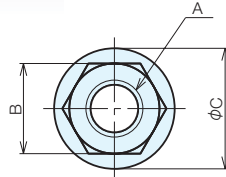

Specifications

Order No.	No.	A (Coarse Thread)	B	C	D	E	F	G	H	I	Weight (g)		
03422	SFNM08	M8×1.25	13	19	12	3	19	4	10	7.8	21		
03423	SFNM10	M10×1.5	17	22	13	3	22	5	12	8.4	32		
03424	SFNM12	M12×1.75	19	25	14.3	4	25	6	14	9.0	46		
03425	SFNM14	M14×2	22	28	17.5	4.5	28	6	16	11.4	66		
03426	SFNM16	M16×2	24	35	20	4.5	35	7	18	12.8	103		
03427	SFNM18	M18×2.5	27	35	20.6	4.5	35	7	20	13.6	106		
03428	SFNM20	M20×2.5	30	42	25	6	42	8	22	16.6	183		
03429	SFNM22	M22×2.5	32	45	25.4	6	45	8	25.4	16.9	210		
03430	SFNM24	M24×3	36	50	28	6	50	8	28	18.7	270		

Usage Examples

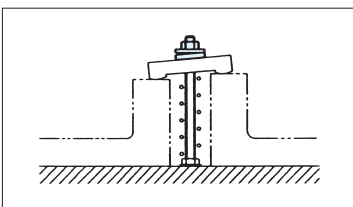

Base Elements

Clamp Units

Clamping Parts

Machine Vises

Drilling Vises

Vibration Isolation

Surface Plates and Measurement Instruments

Index