



RoHS対応

ERON® AMF®

T-SLOT BOLTS

No.E-465


## Tスロットボルト(ハイテンション)

材質 SCM435(鍛造品)

熱処理 焼入HRC30±5

表面処理 黒染め

強度区分 12.9

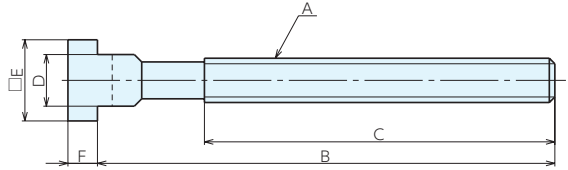

## 仕様・価格表

1本価格

オーダーNo.	No.	適合T溝巾	A(並目)	B	C	D	E	F	質量g	価格
16021	BTH1250	12	M12×1.75	50	35	11.7	18	7	60	1,720
16022	BTH1280	12	M12×1.75	80	55	11.7	18	7	75	1,830
16023	BTH1212	12	M12×1.75	125	75	11.7	18	7	110	2,070
72913	BTH1216	12	M12×1.75	160	100	11.7	18	7	135	2,330
16024	BTH1220	12	M12×1.75	200	120	11.7	18	7	160	2,520
16025	BTH1450	14	M12×1.75	50	35	13.7	22	8	70	1,760
16026	BTH1480	14	M12×1.75	80	55	13.7	22	8	100	1,900
16027	BTH1412	14	M12×1.75	125	75	13.7	22	8	120	2,210
72914	BTH1416	14	M12×1.75	160	100	13.7	22	8	150	2,460
16028	BTH1420	14	M12×1.75	200	120	13.7	22	8	180	2,550
16029	BTH1663	16	M16×2	63	45	15.7	25	9	140	2,250
72915	BTH1680	16	M16×2	80	55	15.7	25	9	160	2,280
16030	BTH1610	16	M16×2	100	65	15.7	25	9	180	2,520
72916	BTH1612	16	M16×2	125	85	15.7	25	9	225	2,760
16031	BTH1616	16	M16×2	160	100	15.7	25	9	260	3,080
72917	BTH1620	16	M16×2	200	125	15.7	25	9	315	3,410
16032	BTH1625	16	M16×2	250	150	15.7	25	9	380	3,760
16033	BTH1863	18	M16×2	63	45	17.7	28	10	160	2,390
16034	BTH1810	18	M16×2	100	65	17.7	28	10	203	2,550
16035	BTH1816	18	M16×2	160	100	17.7	28	10	280	3,220
72918	BTH1820	18	M16×2	200	125	17.7	28	10	330	3,600
16036	BTH1825	18	M16×2	250	150	17.7	28	10	430	3,910
16037	BTH2080	20	M20×2.5	80	55	19.7	32	12	290	3,370
16038	BTH2012	20	M20×2.5	125	85	19.7	32	12	390	3,760
16039	BTH2020	20	M20×2.5	200	125	19.7	32	12	550	4,340
16040	BTH2031	20	M20×2.5	315	190	19.7	32	12	800	6,290
16041	BTH2280	22	M20×2.5	80	55	21.7	35	14	330	3,370
16042	BTH2212	22	M20×2.5	125	85	21.7	35	14	428	3,760
16043	BTH2220	22	M20×2.5	200	125	21.7	35	14	570	4,340
16044	BTH2231	22	M20×2.5	315	190	21.7	35	14	820	6,290
16045	BTH2410	24	M24×3	100	70	23.7	40	16	540	4,620
16046	BTH2416	24	M24×3	160	110	23.7	40	16	770	6,010
16047	BTH2425	24	M24×3	250	150	23.7	40	16	1040	7,400
16048	BTH2440	24	M24×3	400	240	23.7	40	16	1410	10,700