 




Centering Holders

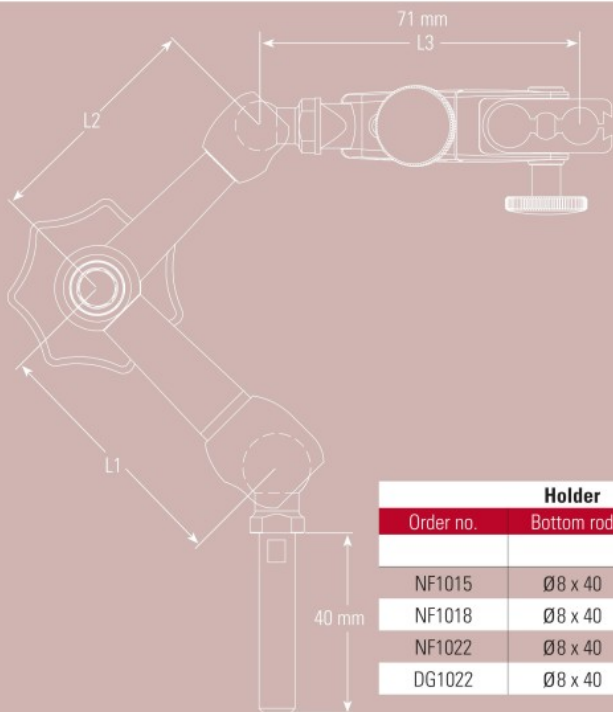

FA1500

FA1510

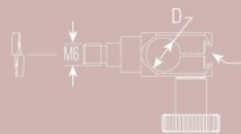

Standard Clamp
FA1100 dia. 8 mm
FA1120 dia. 3/8"

Holder			Arm length			Standard clamp	
Order no.	Bottom rod	Weight [Kg]	Bottom arm	Top arm	Total	Order no.	Dia.
			L1	L2	L1 + L2 + L3		D
NF1015	Ø8 x 40	0.271	56	51	128.5	FA1100	8
NF1018	Ø8 x 40	0.271	56	51	128.5	FA1120	3/8"
NF1022	Ø8 x 40	0.314	56	51	178	FA1500	6, 8, 3/8"
DG1022	Ø8 x 40	0.350	110	101	282	FA1500	6, 8, 3/8"

All measurements are in mm unless otherwise mentioned