

NK-3300

No Welded Type

DN: 15mm(1/2") ~ 50mm(2")

Length: 150mm ~ 3M

*For any other specifications, please contact us.

Flange Standard: JIS, ANSI, DIN, ASME



①	Tube	Stainless Steel
②	Braid	Stainless Steel
③	Flange	Carbon Steel, Stainless Steel
④	Base Block	Carbon Steel, Stainless Steel
⑤	Ring	Carbon Steel, Stainless Steel

NK-4000

(Floating x Fixed Flange)

NK-4100

(Both Ends Floating Flange)


Ribbon Braid Type

DN: 80mm(3") ~ 350mm(14")

Length: 200mm ~ 3M

*For any other specifications, please contact us.

Flange Standard: JIS, ANSI, DIN, ASME

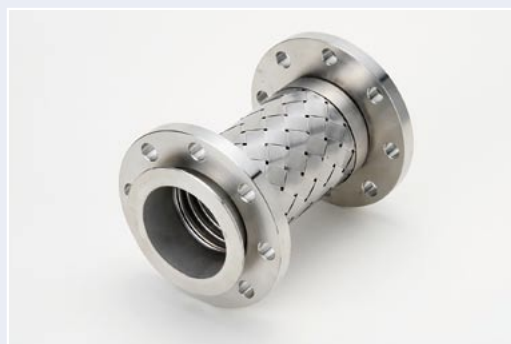

①	Tube	Stainless Steel
②	Braid	Stainless Steel
③	Ring	Carbon Steel, Stainless Steel
④	Stub End	Carbon Steel, Stainless Steel
⑤	Flange	Carbon Steel, Stainless Steel
⑥	End Pipe	Carbon Steel, Stainless Steel

NK-5000

(Floating x Fixed Flange)

NK-5100

(Both Ends Floating Flange)

Band Stopper Type

DN: 80mm(3") ~ 600mm(24")

Length: 300mm ~ 3M

*For any other specifications, please contact us.

Flange Standard: JIS, ANSI, DIN, ASME



①	Tube	Stainless Steel
②	Braid	Stainless Steel
③	Stub End	Carbon Steel, Stainless Steel
④	Flange	Carbon Steel, Stainless Steel
⑤	Neck Ring	Carbon Steel, Stainless Steel
⑥	Band	Carbon Steel, Stainless Steel
⑦	End Pipe	Carbon Steel, Stainless Steel