

NK-7500


Single Bellows

NK-7700


Double Bellows

Outer Cylinder Type

Flange Standard: JIS,ANSI,DIN

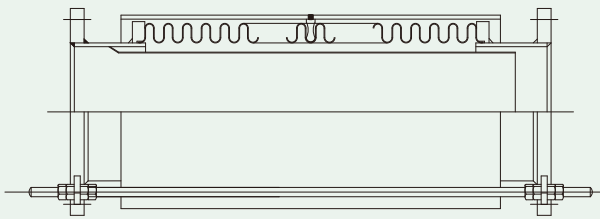

NK-7700

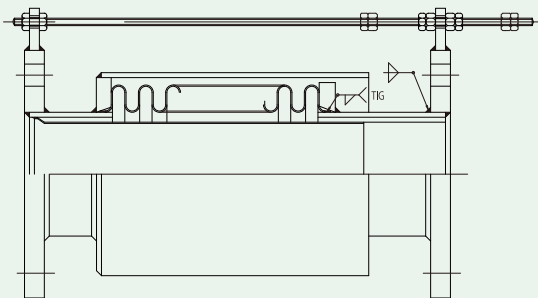

NK-7500

①	Bellows	Stainless Steel
②	Inner Sleeve	Stainless Steel
③	Outer Cylinder	Carbon Steel, Stainless Steel
④	End Pipe	Carbon Steel, Stainless Steel
⑤	Flange	Carbon Steel, Stainless Steel
⑥	Neck Ring	Carbon Steel, Stainless Steel
⑦	Middle Ring	Carbon Steel, Stainless Steel

DN	Length(mm)					
	X=30	X=40	X=50	X=60	X=80	X=100
50mm	560	690	820	960	1370	1630
65mm	450	540	640	730	1070	1260
80mm	600	720	820	900	1330	1550
100mm	560	680	800	900	1320	1550
125mm	500	560	650	710	860	1380
150mm	500	560	650	710	860	1380
200mm	520	580	670	710	860	1380
250mm	520	580	670	710	860	1380
300mm	520	580	670	710	860	1380
350mm	520	580	680	780	1020	1200
400mm	520	580	680	780	1020	1200
450mm	540	600	700	800	1030	1230
500mm	520	590	660	730	870	1160