

NK-7000


Single Bellows

NK-7100


Double Bellows

Reinforced Bellows Type

This product can correspond to high pressure.
Flange Standard: JIS,ANSI,DIN

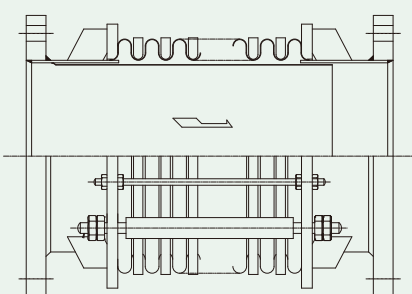

NK-7000

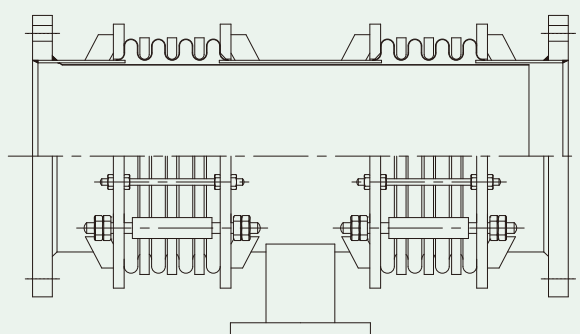

NK-7100

DN	Length(mm)							
	NK-7000				NK-7100			
	X=10	X=20	X=30	X=40	X=50	X=60	X=80	X=100
50mm	320	400	500	570	660	750	1040	1210
65mm	320	400	500	570	660	750	1040	1210
80mm	350	470	570	690	820	900	1300	1530
100mm	350	420	550	650	750	850	1170	1370
125mm	370	430	520	580	640	700	1030	1220
150mm	370	430	520	580	640	700	1030	1220
200mm	370	430	520	580	640	700	1030	1220
250mm	430	470	590	630	720	790	1080	1240
300mm	430	470	590	630	720	790	1080	1240
350mm	430	470	590	630	720	790	1080	1240
400mm	430	470	590	630	720	790	1080	1240
450mm	430	470	590	630	720	790	1080	1240
500mm	500	550	600	650	700	750	1100	1200
550mm	500	550	600	650	700	750	1100	1200
600mm	500	550	600	650	700	750	1100	1200

① Bellows	Stainless Steel
② End Pipe	Carbon Steel, Stainless Steel
③ Inner Sleeve	Stainless Steel
④ Flange	Carbon Steel, Stainless Steel
⑤ Reinforcing Ring	Carbon Steel, Stainless Steel
⑥ Neck Ring	Carbon Steel, Stainless Steel
⑦ Beam	Carbon Steel, Stainless Steel
⑧ Tierod	Carbon Steel, Stainless Steel
⑨ Stopper	Carbon Steel, Stainless Steel
⑩ Set Bolt	Carbon Steel, Stainless Steel