


クイックシールシリーズ インサートタイプ(黄銅仕様)

スィーベルナットメスコネクタ

●ミリサイズ(グループ4)

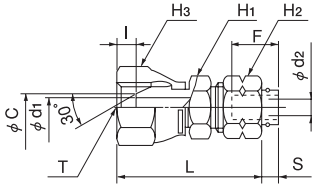

品番	適用チューブ 外径X内径 (mm)	T ねじ サイズ (G)	L (mm)	S (mm)	I (mm)	F チューブ 挿入長さ (mm)	H1 二面幅 (mm)	H2 二面幅 (mm)	H3 二面幅 (mm)	C (mm)	d1 (mm)	d2 最小内径 (mm)	有効断面積 (mm ²)	質量 (g)
SC4N4X2-PF1/8	4X2	G1/8	33.0	4.7	4.0	15	12.0	10.0	14.0	5.0	2.8	0.9	1.0	24.0
SC4N6X4-PF1/8	6X4	G1/8	33.0	4.6	4.0	15	12.0	12.0	14.0	5.0	2.7	2.7	5.0	26.0
SC4N6X4-PF1/4	6X4	G1/4	34.7	4.6	5.7	15	17.0	12.0	19.0	7.0	5.0	2.7	5.5	44.0
SC4N6X4.5-PF1/8	6X4.5	G1/8	33.0	4.6	4.0	15	12.0	12.0	14.0	5.0	3.2	3.2	6.5	26.0
SC4N6X4.5-PF1/4	6X4.5	G1/4	34.7	4.6	5.7	15	17.0	12.0	19.0	7.0	5.0	3.2	7.5	44.0
SC4N8X6-PF1/4	8X6	G1/4	34.6	4.6	5.7	16	17.0	14.0	19.0	7.0	5.0	4.7	17.0	46.0
SC4N10X7.5-PF1/4	10X7.5	G1/4	38.8	4.2	5.7	17	17.0	17.0	19.0	7.0	5.0	6.2	19.0	56.0
SC4N10X7.5-PF3/8	10X7.5	G3/8	40.9	4.2	6.8	17	19.0	17.0	22.0	10.0	6.2	6.2	19.0	71.0
SC4N10X8-PF1/4	10X8	G1/4	38.8	4.2	5.7	17	17.0	17.0	19.0	7.0	5.0	6.7	19.0	56.0
SC4N10X8-PF3/8	10X8	G3/8	40.9	4.2	6.8	17	19.0	17.0	22.0	10.0	6.7	6.7	34.0	71.0
SC4N12X9-PF3/8	12X9	G3/8	41.4	4.8	6.8	18	19.0	19.0	22.0	10.0	7.6	7.6	44.5	54.0
SC4N12X9-PF1/2	12X9	G1/2	46.1	4.8	9.5	18	22.0	19.0	27.0	14.0	10.0	7.6	44.5	116.0

※受注生産品

●インチサイズ(グループ1)

品番	適用 チューブ 外径 (inch)	T ねじ サイズ (G)	L (mm)	S (mm)	I (mm)	F チューブ 挿入長さ (mm)	H1 二面幅 (mm)	H2 二面幅 (mm)	H3 二面幅 (mm)	C (mm)	d1 (mm)	d2 最小内径 (mm)	有効断面積 (mm ²)	質量 (g)
SC1N1/8-PF1/8	1/8	G1/8	33.0	4.6	4.0	15	12.0	8.0	14.0	5.0	1.4	1.4	1.5	22.0
SC1N3/16-PF1/8	3/16	G1/8	33.1	4.6	4.0	15	12.0	10.0	14.0	5.0	2.4	2.4	4.0	24.0
SC1N1/4-PF1/8	1/4	G1/8	33.0	4.6	4.0	15	12.0	12.0	14.0	5.0	3.4	3.4	6.5	25.0
SC1N1/4-PF1/4	1/4	G1/4	34.7	4.6	5.7	15	17.0	12.0	19.0	7.0	5.0	3.4	8.5	44.0
SC1N5/16-PF1/4	5/16	G1/4	34.5	4.6	5.7	16	17.0	14.0	19.0	7.0	5.0	4.7	16.5	45.0
SC1N3/8-PF1/4	3/8	G1/4	38.4	4.6	5.7	17	17.0	17.0	19.0	7.0	5.7	5.7	24.0	55.0
SC1N3/8-PF3/8	3/8	G3/8	40.5	4.6	6.8	17	19.0	17.0	22.0	10.0	5.7	5.7	24.0	72.0
SC1N1/2-PF3/8	1/2	G3/8	41.6	4.6	6.8	18	19.0	19.0	22.0	10.0	8.2	8.2	47.0	70.0
SC1N1/2-PF1/2	1/2	G1/2	46.3	4.6	9.5	18	22.0	19.0	27.0	14.0	10.0	8.2	49.0	104.0
SC1N5/8-PF1/2	5/8	G1/2	52.2	5.1	9.5	23	23.0	27.0	27.0	14.0	10.0	9.3	63.0	145.0


※受注生産品

●インチサイズ(グループ2)

品番	適用 チューブ 外径 (inch)	T ねじ サイズ (G)	L (mm)	S (mm)	I (mm)	F チューブ 挿入長さ (mm)	H1 二面幅 (mm)	H2 二面幅 (mm)	H3 二面幅 (mm)	C (mm)	d1 (mm)	d2 最小内径 (mm)	有効断面積 (mm ²)	質量 (g)
SC2N1/4-PF1/8	1/4	G1/8	33.0	4.6	4.0	15	12.0	12.0	14.0	5.0	2.2	2.2	3.5	25.5
SC2N1/4-PF1/4	1/4	G1/4	34.7	4.6	5.7	15	17.0	12.0	19.0	7.0	5.0	2.2	3.5	44.0
SC2N5/16-PF1/4	5/16	G1/4	34.5	4.6	5.7	16	17.0	14.0	19.0	7.0	5.0	2.9	6.0	45.0
SC2N3/8-PF3/8	3/8	G3/8	40.5	4.6	6.8	17	19.0	17.0	22.0	10.0	5.7	3.5	7.0	72.0
SC2N1/2-PF3/8	1/2	G3/8	41.6	4.6	6.8	18	19.0	19.0	22.0	10.0	5.7	5.2	20.5	70.0

パネルタッチコネクタ

●ミリサイズ(グループ4)

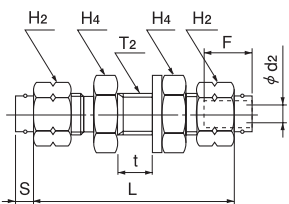

品番	適用 チューブ 外径X内径 (mm)	L (mm)	S (mm)	F チューブ 挿入長さ (mm)	t 大 パネル厚 (mm)	H2 二面幅 (mm)	H4 二面幅 (mm)	d2 最小内径 (mm)	T2 推奨 パネル穴径 (mm)	ワッシャー 外径 (mm)	ワッシャー 肉厚 (mm)	有効断面積 (mm ²)	質量 (g)
UCT4N4X2	4X2	41.5	4.7	15	8.0	10.0	12.0	0.9	9	15	1.6	0.7	25.0
UCT4N4X3	4X3	41.5	4.7	15	8.0	10.0	12.0	2.0	9	15	1.6	3.0	25.0
UCT4N6X4	6X4	42.0	4.6	15	8.4	12.0	14.0	2.7	11	18	1.6	5.0	33.0
UCT4N6X4.5	6X4.5	42.0	4.6	15	8.4	12.0	14.0	3.2	11	18	1.6	7.5	33.0
UCT4N8X6	8X6	43.3	4.6	16	8.4	14.0	17.0	4.7	13	20	2.0	16.0	48.0
UCT4N10X7.5	10X7.5	45.7	4.2	17	8.1	17.0	19.0	6.2	16	24	2.5	30.0	67.0
UCT4N10X8	10X8	45.7	4.2	17	8.1	17.0	19.0	6.7	16	24	2.5	32.0	67.0
UCT4N12X9	12X9	47.3	4.8	18	8.1	19.0	22.0	7.6	18	28	2.5	40.0	87.0

※受注生産品

●インチサイズ(グループ1)

品番	適用 チューブ 外径 (inch)	L (mm)	S (mm)	F チューブ 挿入長さ (mm)	t 大 パネル厚 (mm)	H2 二面幅 (mm)	H4 二面幅 (mm)	d2 最小内径 (mm)	T2 推奨 パネル穴径 (mm)	ワッシャー 外径 (mm)	ワッシャー 肉厚 (mm)	有効断面積 (mm ²)	質量 (g)
UCT1N1/8	1/8	39.7	4.6	15	8.0	8.0	10.0	1.4	7	11	1.6	1.5	14.5
UCT1N3/16	3/16	41.7	4.6	15	8.0	10.0	12.0	2.4	9	15	1.6	4.0	25.0
UCT1N1/4	1/4	42.1	4.6	15	8.4	12.0	14.0	3.4	11	18	1.6	8.5	32.0
UCT1N5/16	5/16	43.2	4.6	16	8.3	14.0	17.0	4.7	13	20	2.0	16.0	49.0
UCT1N3/8	3/8	44.9	4.6	17	7.7	17.0	19.0	5.7	15	24	2.5	22.5	67.0
UCT1N1/2	1/2	47.6	4.6	18	7.8	19.0	22.0	8.2	18	28	2.5	45.0	86.0

※受注生産品

チューブ

クリップ
チューブ

加工チューブ

フッシユウ
継手

クイックシール
継手

クリップ継手
ケミファイット

竹のこ継手

制御切替着脱
シリーズ

治具・工具
付属品

技術資料

参考資料