


MODEL  
**MCNB**

# マイクロ無励磁作動ブレーキ

2形、5形、10形

トルク : 0.2~1.0N・m

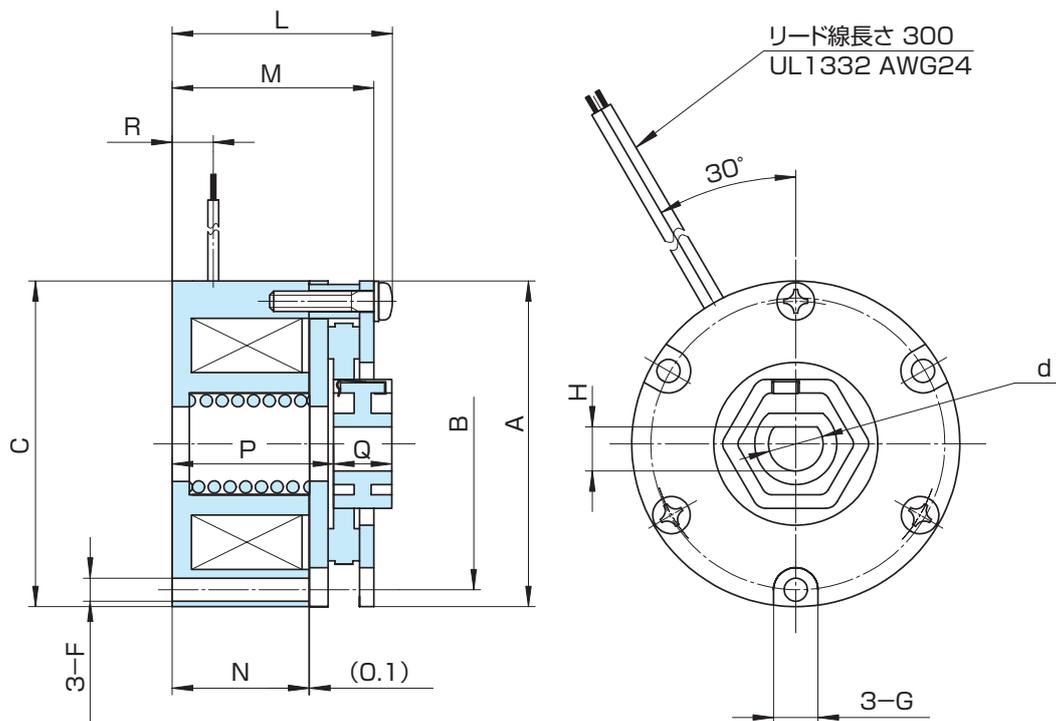

形番		MCNB	2 GS/KS・GR/KR	5 GS/KS・GR/KR	10 GS/KS・GR/KR
静摩擦トルク		[N・m]	0.2	0.5	1.0
慣性		$J \times 10^{-4} [\text{kg} \cdot \text{m}^2]$	0.0026	0.0094	0.0173
穴径		$d_{H9}$	8	8	10
径 方 向	A		40	48	58
	B		35	43	52
	$C_{-0.1}^0$		40	48	58
	F		3	3.4	3.4
	G		6	6.5	7
	$H_{0.1}^{+0.1}$		6.5	6.5	8
軸 方 向	L		29	33	35
	M		26	29.5	32
	N		18	20	22.5
	$P_{-0.1}^{+0.3}$		21	23.6	26
	Q		8.5	8.5	8.5
	R		6	6	6
質		量 [kg]	0.17	0.26	0.42