



# AMD

## Oiles Aramid M Discs

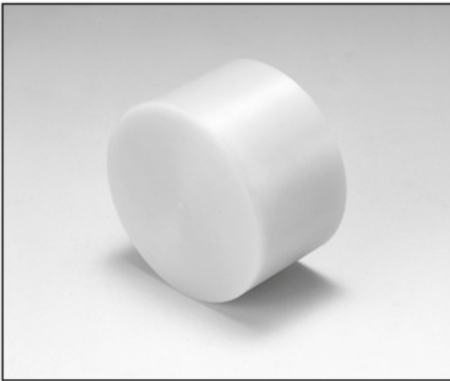

Specify Part No. by required diameter.  
(e.g.) Diameter is 60mm.

**AMD - 60**  
Part No.

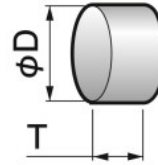

Part No.	Diameter		Length
	φD	Tolerance	T
<b>AMD-30</b>	30	+3.0 +1.0	35
<b>AMD-60</b>	60	+3.0 +1.0	35
<b>AMD-100</b>	100	+3.0 +1.0	35
<b>AMD-160</b>	160	+3.0 +1.0	35


# AMP

## Oiles Aramid M Plate Material



Specify Part No. by required width, length and thickness.  
(e.g.) With is 100mm, length is 200mm, and thickness is 20mm.

**AMP - 10020020**  
Part No.

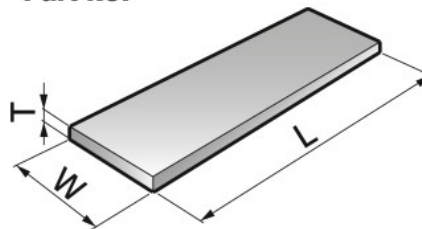

Part No.	Width		Length		Thickness	
	W	Tolerance	L	Tolerance	T	Tolerance
<b>AMP-10010010</b>	100	+5.0 +1.0	100	+5.0 +1.0	10	+3.0 +1.0
<b>AMP-10010015</b>	100	+5.0 +1.0	100	+5.0 +1.0	15	+3.0 +1.0
<b>AMP-10020015</b>	100	+5.0 +1.0	200	+5.0 +1.0	15	+3.0 +1.0
<b>AMP-10020020</b>	100	+5.0 +1.0	200	+5.0 +1.0	20	+3.0 +1.0
<b>AMP-10020030</b>	100	+5.0 +1.0	200	+5.0 +1.0	30	+3.0 +1.0

Part No.	Width		Length		Thickness	
	W	Tolerance	L	Tolerance	T	Tolerance
<b>AMP-20020020</b>	200	+5.0 +1.0	200	+ 5.0 + 1.0	20	+3.0 +1.0
<b>AMP-20020030</b>	200	+5.0 +1.0	200	+ 5.0 + 1.0	30	+3.0 +1.0
<b>AMP-12030020</b>	120	+5.0 +1.0	300	+15.0 + 5.0	20	+3.0 +1.0
<b>AMP-12030030</b>	120	+5.0 +1.0	300	+15.0 + 5.0	30	+3.0 +1.0

※Maximum thickness is 60mm for the width of 100 and 200mm types.