

Reamers

Endmills

Drills

Countersinks/
Counterbores


Metal
Slitting Saws

Cutters

SVMA〈面取ミル〉

面取ミル OKコート

Coated Solid Carbide V-pointed Endmills "MENTOMILL" (2 Flutes)

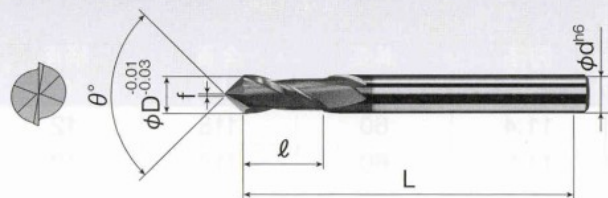


刃数 Number of Flutes	先端角 Point Angle	ネジレ角 Helix Angle	表面処理 Surface Treatment	切削条件 Cutting Conditions
2	90° 120°	30° R	OK-A Premium	P198

●穴の面取り加工に加え、V溝加工、C面加工等の横送り切削も可能です。
Ideal for countersink, chamfering and V slit work.

SVM〈面取ミル〉

面取ミル ノンコート

Coated Solid Carbide V-pointed Endmills "MENTOMILL"

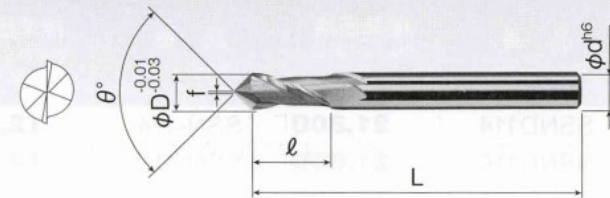

刃数 Number of Flutes	先端角 Point Angle	ネジレ角 Helix Angle	表面処理 Surface Treatment	切削条件 Cutting Conditions
2	90° 120°	30° R		P198

●穴の面取り加工に加え、V溝加工、C面加工等の横送り切削も可能です。
Ideal for countersink, chamfering and V slit work.

先端角90° Point angle 90°

OKコート		ノンコート		寸法 Size				
品番 Product No.	標準価格 Standard price ¥	品番 Product No.	標準価格 Standard price ¥	刃径 D	刃長 ℓ	底刃幅 f	全長 L	柄径 d
SVMA030-090	9,800	SVM-030-090	7,800	3	6	0.2	48	6
SVMA040-090	10,000	SVM-040-090	8,000	4	8	0.25	48	6
SVMA050-090	10,300	SVM-050-090	8,300	5	10	0.3	67	6
SVMA060-090	10,500	SVM-060-090	8,400	6	12	0.4	67	6
SVMA080-090	13,600	SVM-080-090	10,900	8	16	0.5	84	8
SVMA100-090	20,300	SVM-100-090	16,200	10	20	0.6	95	10
SVMA120-090	26,600	SVM-120-090	21,300	12	24	0.8	104	12
SVMA160-090	46,400	SVM-160-090	37,100	16	32	1	132	16
SVMA200-090	78,700	SVM-200-090	63,000	20	40	1.2	140	20

先端角120° Point angle 120°

OKコート		ノンコート		寸法 Size				
品番 Product No.	標準価格 Standard price ¥	品番 Product No.	標準価格 Standard price ¥	刃径 D	刃長 ℓ	底刃幅 f	全長 L	柄径 d
SVMA030-120	9,800	SVM-030-120	7,800	3	6	0.2	48	6
SVMA040-120	10,000	SVM-040-120	8,000	4	8	0.25	48	6
SVMA050-120	10,300	SVM-050-120	8,300	5	10	0.3	67	6
SVMA060-120	10,500	SVM-060-120	8,400	6	12	0.4	67	6
SVMA080-120	13,600	SVM-080-120	10,900	8	16	0.5	84	8
SVMA100-120	20,300	SVM-100-120	16,200	10	20	0.6	95	10
SVMA120-120	26,600	SVM-120-120	21,300	12	24	0.8	104	12
SVMA160-120	46,400	SVM-160-120	37,100	16	32	1	132	16
SVMA200-120	78,700	SVM-200-120	63,000	20	40	1.2	140	20