


BSSG/M

ロウ付千鳥刃サイドカッター

Brazed Staggered Side Milling Cutters

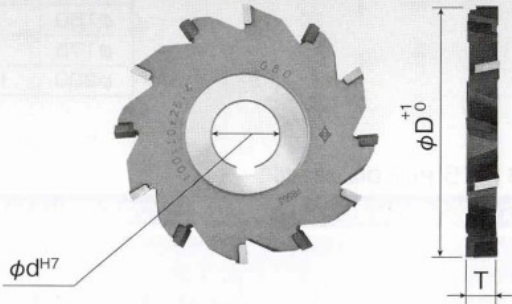

厚み(T)の寸法許容差

Tolerance of thickness(T)

厚み(T) Thickness(T)	許容差 Tolerance
~6.0 6.0 or less	+0.075 0
~10.0 10.0 or less	+0.090 0
~18.0 18.0 or less	+0.110 0
~30.0 30.0 or less	+0.130 0

●チップ材種は、G80(鋼・鋳鉄 兼用)です。
The carbide chip material is G80(for both steel and cast iron).



穴径φ25.4 Hole Dia.φ25.4

品番 Product No.		寸法 Size				標準価格 Standard price ¥
G80	M80※	外径 D	厚み T	穴径 d	刃数 NT	
BSSGT075X04	BSSMT075X04	75	4	25.4	10	29,300
BSSGT075X05	BSSMT075X05	75	5	25.4	10	29,300
BSSGT075X06	BSSMT075X06	75	6	25.4	10	29,800
BSSGT075X07	BSSMT075X07	75	7	25.4	10	31,900
BSSGT075X08	BSSMT075X08	75	8	25.4	10	31,900
BSSGT075X09	BSSMT075X09	75	9	25.4	10	35,900
BSSGT075X10	BSSMT075X10	75	10	25.4	10	35,900
BSSGT075X11	BSSMT075X11	75	11	25.4	10	36,500
BSSGT075X12	BSSMT075X12	75	12	25.4	10	36,500
BSSGT075X13	BSSMT075X13	75	13	25.4	10	42,000
BSSGT075X14	BSSMT075X14	75	14	25.4	10	42,000
BSSGT075X15	BSSMT075X15	75	15	25.4	10	43,100
BSSGT075X16	BSSMT075X16	75	16	25.4	10	43,100
BSSGT075X17	BSSMT075X17	75	17	25.4	10	46,000
BSSGT075X18	BSSMT075X18	75	18	25.4	10	46,000
BSSGT075X20	BSSMT075X20	75	20	25.4	10	49,200
BSSGT075X22	BSSMT075X22	75	22	25.4	10	67,000
BSSGT075X24	BSSMT075X24	75	24	25.4	10	71,800
BSSGT075X25	BSSMT075X25	75	25	25.4	10	79,500
BSSGT100X04	BSSMT100X04	100	4	25.4	12	39,500
BSSGT100X05	BSSMT100X05	100	5	25.4	12	37,100
BSSGT100X06	BSSMT100X06	100	6	25.4	12	37,100
BSSGT100X07	BSSMT100X07	100	7	25.4	12	38,800
BSSGT100X08	BSSMT100X08	100	8	25.4	12	38,800
BSSGT100X09	BSSMT100X09	100	9	25.4	12	42,000
BSSGT100X10	BSSMT100X10	100	10	25.4	12	42,000
BSSGT100X11	BSSMT100X11	100	11	25.4	12	44,800
BSSGT100X12	BSSMT100X12	100	12	25.4	12	44,800
BSSGT100X13	BSSMT100X13	100	13	25.4	12	52,000
BSSGT100X14	BSSMT100X14	100	14	25.4	12	52,000
BSSGT100X15	BSSMT100X15	100	15	25.4	12	52,000
BSSGT100X16	BSSMT100X16	100	16	25.4	12	55,200
BSSGT100X17	BSSMT100X17	100	17	25.4	12	60,900
BSSGT100X18	BSSMT100X18	100	18	25.4	12	60,900
BSSGT100X20	BSSMT100X20	100	20	25.4	12	64,700

※BSSMT(M80)は生産終了につき在庫限りとなります。

品番 Product No.		寸法 Size				標準価格 Standard price ¥
G80	M80※	外径 D	厚み T	穴径 d	刃数 NT	
BSSGT100X22	BSSMT100X22	100	22	25.4	12	70,700
BSSGT100X24	BSSMT100X24	100	24	25.4	12	75,800
BSSGT100X25	BSSMT100X25	100	25	25.4	12	83,500
BSSGT125X04	BSSMT125X04	125	4	25.4	14	51,300
BSSGT125X05	BSSMT125X05	125	5	25.4	14	48,500
BSSGT125X06	BSSMT125X06	125	6	25.4	14	48,500
BSSGT125X07	BSSMT125X07	125	7	25.4	14	49,700
BSSGT125X08	BSSMT125X08	125	8	25.4	14	49,700
BSSGT125X09	BSSMT125X09	125	9	25.4	14	53,800
BSSGT125X10	BSSMT125X10	125	10	25.4	14	53,800
BSSGT125X11	BSSMT125X11	125	11	25.4	14	56,900
BSSGT125X12	BSSMT125X12	125	12	25.4	14	56,900
BSSGT125X13	BSSMT125X13	125	13	25.4	14	68,600
BSSGT125X14	BSSMT125X14	125	14	25.4	14	68,600
BSSGT125X15	BSSMT125X15	125	15	25.4	14	69,600
BSSGT125X16	BSSMT125X16	125	16	25.4	14	72,400
BSSGT125X18	BSSMT125X18	125	18	25.4	14	78,500
BSSGT125X20	BSSMT125X20	125	20	25.4	14	86,800
BSSGT125X22	BSSMT125X22	125	22	25.4	14	92,300
BSSGT125X24	BSSMT125X24	125	24	25.4	14	99,400
BSSGT125X25	BSSMT125X25	125	25	25.4	14	110,400
BSSGT150X04	BSSMT150X04	150	4	25.4	16	68,600
BSSGT150X05	BSSMT150X05	150	5	25.4	16	62,400
BSSGT150X06	BSSMT150X06	150	6	25.4	16	62,400
BSSGT150X07	BSSMT150X07	150	7	25.4	16	62,400
BSSGT150X08	BSSMT150X08	150	8	25.4	16	62,400
BSSGT150X09	BSSMT150X09	150	9	25.4	16	66,400
BSSGT150X10	BSSMT150X10	150	10	25.4	16	66,400
BSSGT150X11	BSSMT150X11	150	11	25.4	16	69,300
BSSGT150X12	BSSMT150X12	150	12	25.4	16	69,300
BSSGT150X13	BSSMT150X13	150	13	25.4	16	83,500
BSSGT150X14	BSSMT150X14	150	14	25.4	16	83,500
BSSGT150X15	BSSMT150X15	150	15	25.4	16	87,200
BSSGT150X16	BSSMT150X16	150	16	25.4	16	87,200
BSSGT150X18	BSSMT150X18	150	18	25.4	16	95,700

リーマ

エンドミル

ドリル

面取り/
座ぐり

メタルソー

カッター