




NDX Jobber Drills - Heavy Duty

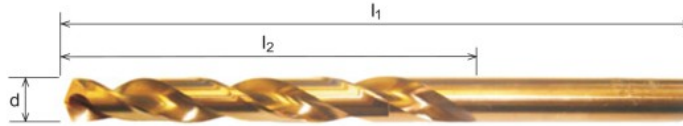

Code
177

Properties		
M INCH	DIN 338	HSS Co5
	TYPE N	
	33°	GOLD OXIDE
	STANDARD POINT sizes below 1.5 mm	
	SPLIT POINT 1.5 mm and above	



**JOBBER DRILL SET
IN METAL CASE**

Size Range	No. of drills	Code
1 - 13 x 0.5	25	1770025

d		l ₂	l ₁	Code
mm	inch			
1		12	34	1770100
1.5		18	40	1770150
1.587	1/16	20	43	1770159
1.6		20	43	1770160
1.7		20	43	1770170
1.8		22	46	1770180
1.9		22	46	1770190
1.984	5/64	24	49	1770198
2		24	49	1770200
2.1		24	49	1770210
2.2		27	53	1770220
2.3		27	53	1770230
2.381	3/32	30	57	1770238
2.4		30	57	1770240
2.5		30	57	1770250
2.6		30	57	1770260
2.7		33	61	1770270
2.778	7/64	33	61	1770278
2.8		33	61	1770280
2.9		33	61	1770290
3		33	61	1770300
3.175	1/8	36	65	1770318
3.2		36	65	1770320
3.3		36	65	1770330
3.4		39	70	1770340
3.5		39	70	1770350
3.572	9/64	39	70	1770357
3.6		39	70	1770360
3.7		39	70	1770370
3.8		43	75	1770380
3.9		43	75	1770390
3.969	5/32	43	75	1770397
4		43	75	1770400
4.1		43	75	1770410
4.2		43	75	1770420
4.3		47	80	1770430
4.366	11/64	47	80	1770437
4.4		47	80	1770440
4.5		47	80	1770450

d		l ₂	l ₁	Code
mm	inch			
4.6		47	80	1770460
4.7		47	80	1770470
4.762	3/16	52	86	1770476
4.8		52	86	1770480
4.9		52	86	1770490
5		52	86	1770500
5.1		52	86	1770510
5.159	13/64	52	86	1770516
5.2		52	86	1770520
5.3		52	86	1770530
5.4		57	93	1770540
5.5		57	93	1770550
5.556	7/32	57	93	1770556
5.6		57	93	1770560
5.7		57	93	1770570
5.8		57	93	1770580
5.9		57	93	1770590
5.953	15/64	57	93	1770595
6		57	93	1770600
6.1		63	101	1770610
6.2		63	101	1770620
6.3		63	101	1770630
6.350	1/4	63	101	1770635
6.4		63	101	1770640
6.5		63	101	1770650
6.6		63	101	1770660
6.7		63	101	1770670
6.747	17/64	69	109	1770675
6.8		69	109	1770680
6.9		69	109	1770690
7		69	109	1770700
7.1		69	109	1770710
7.2		69	109	1770720
7.3		69	109	1770730
7.4		69	109	1770740
7.5		69	109	1770750
7.541	19/64	75	117	1770754
7.6		75	117	1770760
7.7		75	117	1770770
7.8		75	117	1770780
7.9		75	117	1770790
7.937	5/16	75	117	1770794
8		75	117	1770800
8.1		75	117	1770810
8.2		75	117	1770820
8.3		75	117	1770830
8.334	21/64	75	117	1770833
8.4		75	117	1770840
8.5		75	117	1770850
8.6		81	125	1770860



**STRAIGHT
SHANK
DRILLS**

Continued on next page...