

25F-RE
Graduation: 0.001mm
Range: 2mm

- Equipped spindle pull-up release (RE-2) 280mm long
- Flat back




25S
Graduation: 0.001mm
Range: 2mm

- Small dial face type (φ 55.7mm)
- Lug back



55
Graduation: 0.001mm
Range: 5mm

- Lug back

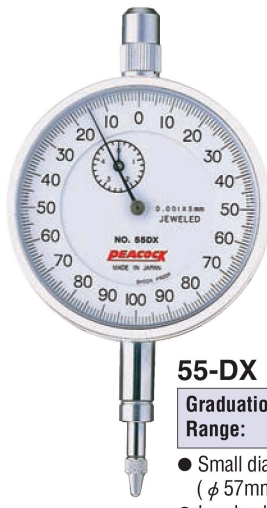

55-DX
Graduation: 0.001mm
Range: 5mm

- Small dial face type (φ 57mm)
- Lug back



56
Graduation: 0.005mm
Range: 5mm

- Lug back

Specifications

(unit: μm)

Model	Graduation (mm)	Range (mm)	Reading	Indication error					Retrace error	Repeatability	Measuring force less than (N)
				1/10 revolution	1/2 revolution	One revolution	Two revolutions	Whole measuring range			
5B-HG	0.001	1	0 - 100 - 0	2	±2	±3	±3	±3	2	0.5	1.5
5-DX	0.001	1	0 - 100 - 0	2.5	±3	±4	±4	±5	3	0.5	1.5
5B	0.001	1	0 - 100 - 0	2.5	±3	±4	±4	±5	3	0.5	1.5
5F	0.001	1	0 - 100 - 0	2.5	±3	±4	±4	±5	3	0.5	1.5
5-SWF	0.001	1	0 - 100 - 0	2.5	±3	±4	±4	±5	3	0.5	1.5
25	0.001	2	±0 - 100 - 100	4	±5	±6	±6	±7	3	0.5	1.5
25F-RE	0.001	2	±0 - 100 - 100	4	±5	±6	±6	±7	3	0.5	1.5
25S	0.001	2	0 - 100 - 0	4	±5	±6	±6	±7	3	0.5	1.5
55	0.001	5	0 - 100 - 0	5	±6	±7	±8	±10	4	1	1.5
55-DX	0.001	5	0 - 100 - 0	5	±6	±7	±8	±10	4	1	1.5
56	0.005	5	0 - 25 - 50	6	±10	±10	±12	±12	5	5	1.5