


P-MC

メイルコネクタ

MALE CONNECTOR

Indicates width of union nut
ユニオンナット2面幅

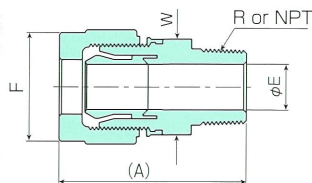

ミリチューブ - Rネジタイプ

| 製品 No. PART.No. | 適用チューブ Tube Size | 管用ネジ Thread Size | (A) | φE | F | W |
|--------------------|---------------------|---------------------|--------------|-----|------|------|
| mm tube type (R) | | | Dimension:mm | | | |
| ※ P - MC 3 - 1B | 3 × 2 | R 1/8 | 31 | 2.1 | 12 | 12 |
| ※ P - MC 3 - 2B | " | R 1/4 | 35 | " | " | " |
| ※ P - MC 3 - 3A | " | R 3/8 | " | " | " | 19 |
| ※ P - MC 3 - 4A | " | R 1/2 | 39 | " | " | 23 |
| ※ P - MC 4 - 1B | 4 × 3 | R 1/8 | 30.5 | 3.1 | 12 | 12 |
| ※ P - MC 4 - 2B | " | R 1/4 | 34.5 | " | " | " |
| ※ P - MC 4 - 3A | " | R 3/8 | " | " | " | 19 |
| ※ P - MC 4 - 4A | " | R 1/2 | 38.5 | " | " | 23 |
| P - MC 6 - 1B | 6 × 4 | R 1/8 | 35 | 4 | 16 | 15 |
| P - MC 6 - 2B | " | R 1/4 | 39 | " | " | " |
| P - MC 6 - 3B | " | R 3/8 | " | " | " | " |
| P - MC 6 - 4A | " | R 1/2 | 43 | " | " | 23 |
| P - MC 6 - 6A | " | R 3/4 | 48 | " | " | 28 |
| P - MC 8 - 1B | 8 × 6 | R 1/8 | 38 | 4 | 19 | 18 |
| P - MC 8 - 2B | " | R 1/4 | 42 | 6 | " | " |
| P - MC 8 - 3B | " | R 3/8 | " | " | " | " |
| P - MC 8 - 4B | " | R 1/2 | 46 | " | " | " |
| P - MC 8 - 6A | " | R 3/4 | 51 | 16 | " | 28 |
| P - MC 10 - 1B | 10 × 8 | R 1/8 | 41 | 4 | 23 | 21 |
| P - MC 10 - 2B | " | R 1/4 | 45 | 6 | " | " |
| P - MC 10 - 3B | " | R 3/8 | " | 8 | " | " |
| P - MC 10 - 4B | " | R 1/2 | 49 | " | " | " |
| P - MC 10 - 6A | " | R 3/4 | 54 | " | " | 28 |
| P - MC 12 - 1A | 12 × 10 | R 1/8 | 45 | 4.4 | 28 | 25 |
| P - MC 12 - 2B | " | R 1/4 | 49 | 6 | " | " |
| P - MC 12 - 3B | " | R 3/8 | " | 10 | " | " |
| P - MC 12 - 4B | " | R 1/2 | 53 | " | " | " |
| P - MC 12 - 6B | " | R 3/4 | 55 | " | " | " |
| P - MC 12 - 8A | " | R 1 | 67 | " | " | 35 |
| P - MC 19 - 2A | 19 × 15.8 | R 1/4 | 59 | 6 | 38 | 33.5 |
| P - MC 19 - 3B | " | R 3/8 | " | 10 | " | " |
| P - MC 19 - 4B | " | R 1/2 | 63 | 12 | " | " |
| P - MC 19 - 6B | " | R 3/4 | 65 | 16 | " | " |
| P - MC 19 - 8B | " | R 1 | 68 | " | " | " |
| P - MC 25 - 3A | 25 × 22 | R 3/8 | 71 | 10 | 47.5 | 43 |
| P - MC 25 - 4A | " | R 1/2 | 75 | 12 | " | " |
| P - MC 25 - 6B | " | R 3/4 | 77 | 16 | " | " |
| P - MC 25 - 8B | " | R 1 | 80 | 22 | " | " |

インチチューブ - NPTネジタイプ

| Inch tube type (NPT) | | | Dimension:mm | | | |
|----------------------|---------------|----------|--------------|-----|------|------|
| ※ P - MC W1 - N1B | 1/8" × 0.086" | NPT 1/8" | 31 | 2.1 | 12 | 12 |
| ※ P - MC W1 - N2B | " | NPT 1/4" | 35 | " | " | " |
| ※ P - MC W1 - N3A | " | NPT 3/8" | " | " | " | 19 |
| ※ P - MC W1 - N4A | " | NPT 1/2" | 39 | " | " | 23 |
| P - MC W2 - N1B | 1/4" × 5/32" | NPT 1/8" | 35 | 4 | 16 | 15 |
| P - MC W2 - N2B | " | NPT 1/4" | 39 | " | " | " |
| P - MC W2 - N3B | " | NPT 3/8" | " | " | " | " |
| P - MC W2 - N4A | " | NPT 1/2" | 43 | " | " | 23 |
| P - MC W2 - N6A | " | NPT 3/4" | 48 | " | " | 28 |
| P - MC W3 - N1B | 3/8" × 1/4" | NPT 1/8" | 41 | 4 | 23 | 21 |
| P - MC W3 - N2B | " | NPT 1/4" | 45 | 6 | " | " |
| P - MC W3 - N3B | " | NPT 3/8" | " | 8 | " | " |
| P - MC W3 - N4B | " | NPT 1/2" | 49 | " | " | " |
| P - MC W3 - N6A | " | NPT 3/4" | 54 | " | " | 28 |
| P - MC W4 - N1A | 1/2" × 3/8" | NPT 1/8" | 45 | 4.4 | 28 | 25 |
| P - MC W4 - N2B | " | NPT 1/4" | 49 | 6 | " | " |
| P - MC W4 - N3B | " | NPT 3/8" | " | 10 | " | " |
| P - MC W4 - N4B | " | NPT 1/2" | 53 | " | " | " |
| P - MC W4 - N6B | " | NPT 3/4" | 55 | " | " | " |
| P - MC W4 - N8A | " | NPT 1" | 67 | " | " | 35 |
| P - MC W6 - N2A | 3/4" × 5/8" | NPT 1/4" | 59 | 6 | 38 | 33.5 |
| P - MC W6 - N3B | " | NPT 3/8" | " | 10 | " | " |
| P - MC W6 - N4B | " | NPT 1/2" | 63 | 12 | " | " |
| P - MC W6 - N6B | " | NPT 3/4" | 65 | 16 | " | " |
| P - MC W6 - N8B | " | NPT 1" | 68 | " | " | " |
| P - MC W8 - N3A | 1" × 7/8" | NPT 3/8" | 71 | 10 | 47.5 | 43 |
| P - MC W8 - N4A | " | NPT 1/2" | 75 | 12 | " | " |
| P - MC W8 - N6B | " | NPT 3/4" | 77 | 16 | " | " |
| P - MC W8 - N8B | " | NPT 1" | 80 | 22 | " | " |

・全ての寸法は参考値です。
 ・Wは本体2面幅を示します。
 ・※印の製品No. については、4頁に掲載の「※一部小口径品について」を参照下さい。
 ・All dimensions are for reference only.
 ・"W" means width of surface distance.
 ・※mark items : Please refer to page 4.