


# Super 300 Type Pillarfitting® “Pseries”

P-ME

## メイルエルボ MALE ELBOW

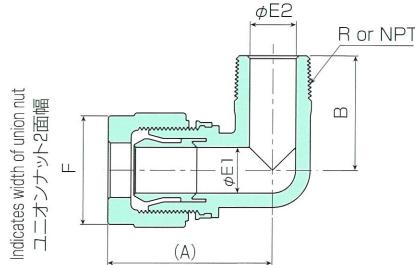

ミリチューブ - Rネジタイプ

製品No. PART.No.	適用チューブ Tube Size	管用ネジ Thread Size	(A)	B	φE1	φE2	F	W
mm tube type (R)								
※ P - ME 3 - 1B	3 × 2	R 1/8	23	18.5	2.1	2.1	12	8
※ P - ME 3 - 2B	"	R 1/4	"	22.5	"	"	"	"
※ P - ME 3 - 3A	"	R 3/8	25	19.5	"	10	"	20
※ P - ME 3 - 4A	"	R 1/2	26.5	22	"	12	"	23
※ P - ME 4 - 1B	4 × 3	R 1/8	22.5	18.5	3.1	3.1	12	8
※ P - ME 4 - 2B	"	R 1/4	"	22.5	"	"	"	"
※ P - ME 4 - 3A	"	R 3/8	24.5	18	"	10	"	20
※ P - ME 4 - 4A	"	R 1/2	26	22	"	12	"	23
P - ME 6 - 1B	6 × 4	R 1/8	30	21	4	4	16	10
P - ME 6 - 2B	"	R 1/4	"	25	"	"	"	"
P - ME 6 - 3B	"	R 3/8	31.5	26.5	"	"	"	13
P - ME 6 - 4A	"	R 1/2	30.5	"	"	12	"	23
P - ME 6 - 6A	"	R 3/4	33	"	"	16	"	28
P - ME 8 - 1B	8 × 6	R 1/8	34.5	22.5	6	4	19	13
P - ME 8 - 2B	"	R 1/4	"	26.5	"	6	"	"
P - ME 8 - 3B	"	R 3/8	"	"	"	"	"	"
P - ME 8 - 4B	"	R 1/2	36	32	"	"	"	15
P - ME 8 - 6A	"	R 3/4	"	28	"	16	"	28
P - ME 10 - 1B	10 × 8	R 1/8	39.5	24	8	4	23	15
P - ME 10 - 2B	"	R 1/4	"	28	"	6	"	"
P - ME 10 - 3B	"	R 3/8	"	"	"	8	"	"
P - ME 10 - 4B	"	R 1/2	"	32	"	"	"	"
P - ME 10 - 6A	"	R 3/4	39	29.5	"	16	"	28
P - ME 12 - 1A	12 × 10	R 1/8	35.5	22.5	10	4.4	28	25
P - ME 12 - 2B	"	R 1/4	45.5	30	"	6	"	18
P - ME 12 - 3B	"	R 3/8	"	"	"	10	"	"
P - ME 12 - 4B	"	R 1/2	"	34	"	"	"	"
P - ME 12 - 6B	"	R 3/4	"	36	"	"	"	"
P - ME 12 - 8A	"	R 1	46.5	35.5	"	22.2	"	35
P - ME 19 - 2A	19 × 15.8	R 1/4	44.5	32.4	16	6	38	33.5
P - ME 19 - 3B	"	R 3/8	57	34	"	10	"	27
P - ME 19 - 4B	"	R 1/2	"	38	"	12	"	"
P - ME 19 - 6B	"	R 3/4	"	40	"	16	"	"
P - ME 19 - 8A	"	R 1	53.5	39.8	"	"	"	35
P - ME 25 - 3A	25 × 22	R 3/8	53	34.5	22	10	47.5	43
P - ME 25 - 4A	"	R 1/2	54.5	40	"	12	"	"
P - ME 25 - 6B	"	R 3/4	69.5	45	"	16	"	34
P - ME 25 - 8B	"	R 1	"	49	"	22	"	"

インチチューブ - NPTネジタイプ

Inch tube type (NPT)								Dimension:mm
※ P - ME W1 - N1B	1/8" × 0.086"	NPT 1/8"	23	18.5	2.1	2.1	12	8
※ P - ME W1 - N2B	"	NPT 1/4"	"	22.5	"	"	"	"
※ P - ME W1 - N3A	"	NPT 3/8"	25	19.5	"	10	"	20
※ P - ME W1 - N4A	"	NPT 1/2"	26.5	22	"	12	"	23
P - ME W2 - N1B	1/4" × 5/32"	NPT 1/8"	30	21	4	4	16	10
P - ME W2 - N2B	"	NPT 1/4"	"	25	"	"	"	"
P - ME W2 - N3B	"	NPT 3/8"	31.5	26.5	"	"	"	13
P - ME W2 - N4A	"	NPT 1/2"	30.5	24.5	"	12	"	23
P - ME W2 - N6A	"	NPT 3/4"	33	26.5	"	16	"	28
P - ME W3 - N1B	3/8" × 1/4"	NPT 1/8"	39.5	24	8	4	23	15
P - ME W3 - N2B	"	NPT 1/4"	"	28	"	6	"	"
P - ME W3 - N3B	"	NPT 3/8"	"	"	"	8	"	"
P - ME W3 - N4B	"	NPT 1/2"	"	32	"	"	"	"
P - ME W3 - N6A	"	NPT 3/4"	39	29.5	"	16	"	28
P - ME W4 - N1A	1/2" × 3/8"	NPT 1/8"	35.5	23.9	10	4.4	28	25
P - ME W4 - N2B	"	NPT 1/4"	45.5	30	"	6	"	18
P - ME W4 - N3B	"	NPT 3/8"	"	"	"	10	"	"
P - ME W4 - N4B	"	NPT 1/2"	"	34	"	"	"	"
P - ME W4 - N6B	"	NPT 3/4"	"	36	"	"	"	"
P - ME W4 - N8A	"	NPT 1"	46.5	35.5	"	22	"	35
P - ME W6 - N2A	3/4" × 5/8"	NPT 1/4"	44.5	32.4	16	6	38	33.5
P - ME W6 - N3B	"	NPT 3/8"	57	34	"	10	"	27
P - ME W6 - N4B	"	NPT 1/2"	"	38	"	12	"	"
P - ME W6 - N6B	"	NPT 3/4"	"	40	"	16	"	"
P - ME W6 - N8A	"	NPT 1"	53.5	39.8	"	"	"	35
P - ME W8 - N3A	1" × 7/8"	NPT 3/8"	53	34.5	22	10	47.5	43
P - ME W8 - N4A	"	NPT 1/2"	54.5	41	"	12	"	"
P - ME W8 - N6B	"	NPT 3/4"	69.5	45	"	16	"	34
P - ME W8 - N8B	"	NPT 1"	"	49	"	22	"	"

・全ての寸法は参考値です。

・Wは本体2面幅を示します。

・※印の製品No.については、4頁に掲載の「※一部小口径品について」を参照下さい。

・All dimensions are for reference only.

・"W" means width of surface distance.

・※印の製品No.については、4頁に掲載の「※一部小口径品について」を参照下さい。