


P-MRT

メイルランティ
MALE RUN TEE

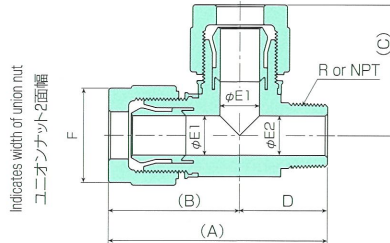

製品 No.	適用チューブ	管用ネジ	(A)	(B)	(C)	D	φE1	φE2	F	W
PART.No.	Tube Size	Thread Size								
mm tube type										
Dimension:mm										
※ P - MRT 3 - 1A	3 × 2	R 1/8	35	20.5	20.5	14.5	2.1	4.4	12	11
※ P - MRT 3 - 2A	"	R 1/4	42	22	22	20	"	6	"	14
※ P - MRT 4 - 1A	4 × 3	R 1/8	34.5	20	20	14.5	3.1	4.4	12	11
※ P - MRT 4 - 2A	"	R 1/4	41.5	21.5	21.5	20	"	6	"	14
P - MRT 6 - 1A	6 × 4	R 1/8	44	26.5	26.5	17.5	4	4	16	15
P - MRT 6 - 2A	"	R 1/4	47.5	"	27.5	21	"	6	"	17
P - MRT 6 - 3A	"	R 3/8	"	"	29	"	"	10	"	19.5
P - MRT 8 - 1A	8 × 6	R 1/8	50.5	31.5	31.5	19	6	4	19	19
P - MRT 8 - 2A	"	R 1/4	54	"	"	22.5	"	6	"	"
P - MRT 8 - 3A	"	R 3/8	"	"	32	"	"	10	"	19.5
P - MRT 8 - 4A	"	R 1/2	58	"	33.5	26.5	"	12	"	23
P - MRT 10 - 1A	10 × 8	R 1/8	57	36	36	21	8	4	23	22
P - MRT 10 - 2A	"	R 1/4	61	"	"	25	"	6	"	"
P - MRT 10 - 3A	"	R 3/8	"	"	"	"	"	10	"	"
P - MRT 10 - 4A	"	R 1/2	64	"	36.5	28	"	12	"	23
P - MRT 12 - 2A	12 × 10	R 1/4	69	41.5	41.5	27.5	10	6	28	25
P - MRT 12 - 3A	"	R 3/8	"	"	"	"	"	10	"	"
P - MRT 12 - 4A	"	R 1/2	72.5	"	"	31	"	12	"	"
P - MRT 12 - 6A	"	R 3/4	73.5	"	43	32	"	16	"	28
P - MRT 19 - 2A	19 × 15.8	R 1/4	82.5	53	53	29.8	16	6	38	33.5
P - MRT 19 - 3A	"	R 3/8	84	"	"	31.3	"	10	"	"
P - MRT 19 - 4A	"	R 1/2	87.5	"	"	34.8	"	12	"	"
P - MRT 19 - 6A	"	R 3/4	88.5	"	"	35.8	"	16	"	"
P - MRT 25 - 6A	25 × 22	R 3/4	105.5	64.5	64.5	41	22	16	47.5	43
P - MRT 25 - 8A	"	R 1	109	"	"	44.5	"	22	"	"
Inch tube type										
Dimension:mm										
※ P - MRT W1 - N1A	1/8" × 0.086"	NPT 1/8"	35	20.5	20.5	14.5	2.1	4.4	12	11
※ P - MRT W1 - N2A	"	NPT 1/4"	42	22	22	20	"	6	"	14
P - MRT W2 - N1A	1/4" × 5/32"	NPT 1/8"	44	26.5	26.5	17.5	4	4	16	15
P - MRT W2 - N2A	"	NPT 1/4"	47.5	"	27.5	21	"	6	"	17
P - MRT W2 - N3A	"	NPT 3/8"	"	"	29	"	"	10	"	19.5
P - MRT W3 - N1A	3/8" × 1/4"	NPT 1/8"	57	36	36	21	8	4	23	22
P - MRT W3 - N2A	"	NPT 1/4"	61	"	"	25	"	6	"	"
P - MRT W3 - N3A	"	NPT 3/8"	"	"	"	"	"	10	"	"
P - MRT W3 - N4A	"	NPT 1/2"	64	"	36.5	28	"	12	"	23
P - MRT W4 - N2A	1/2" × 3/8"	NPT 1/4"	69	41.5	41.5	27.5	10	6	28	25
P - MRT W4 - N3A	"	NPT 3/8"	"	"	"	"	"	10	"	"
P - MRT W4 - N4A	"	NPT 1/2"	72.5	"	"	31	"	12	"	"
P - MRT W4 - N6A	"	NPT 3/4"	73.5	"	43	32	"	16	"	28
P - MRT W6 - N2A	3/4" × 5/8"	NPT 1/4"	82.5	53	53	29.8	16	6	38	33.5
P - MRT W6 - N3A	"	NPT 3/8"	84	"	"	31.3	"	10	"	"
P - MRT W6 - N4A	"	NPT 1/2"	87.5	"	"	34.8	"	12	"	"
P - MRT W6 - N6A	"	NPT 3/4"	88.5	"	"	35.8	"	16	"	"
P - MRT W8 - N6A	1" × 7/8"	NPT 3/4"	105.5	64.5	64.5	41	22	16	47.5	43
P - MRT W8 - N8A	"	NPT 1"	109	"	"	44.5	"	22	"	"

- ミリチューブタイプでNPTネジ、インチチューブタイプでRネジも製作可能ですのでお問合せ下さい。
- 全ての寸法は参考値です。
- Wは本体2面幅を示します。
- ※印の製品No. については、4頁に掲載の「※一部小口径品について」を参照下さい。
- Special items are available.
- All dimensions are for reference only.
- "W" means width of surface distance.
- ※mark items : Please refer to page 4.