


P-FRT

フィメールランティ
FEMALE RUN TEE

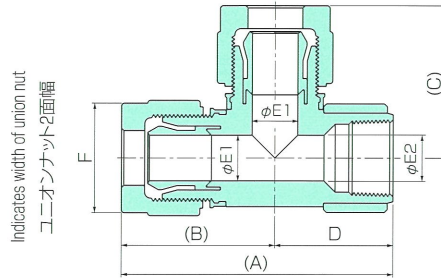

製品 No.	適用チューブ	管用ネジ	(A)	(B)	(C)	D	φE1	φE2	F	W
PART.No.	Tube Size	Thread Size								
mm tube type										Dimension:mm
※ P - FRT 3 - 1A	3 × 2	Rc 1/8	46	23.5	23.5	22.5	2.1	6	12	17
※ P - FRT 3 - 2A	"	Rc 1/4	50	24.5	24.5	25.5	"	8	"	19
※ P - FRT 4 - 1A	4 × 3	Rc 1/8	45.5	23	23	22.5	3.1	6	12	17
※ P - FRT 4 - 2A	"	Rc 1/4	49.5	24	24	25.5	"	8	"	19
P - FRT 6 - 1A	6 × 4	Rc 1/8	48	26.5	27.5	21.5	4	4	16	17
P - FRT 6 - 2A	"	Rc 1/4	50	"	28.5	23.5	"	"	"	19
P - FRT 6 - 3A	"	Rc 3/8	52	"	30	25.5	"	"	"	22
P - FRT 8 - 1A	8 × 6	Rc 1/8	54	31	31	23	6	6	19	18
P - FRT 8 - 2A	"	Rc 1/4	56	"	31.5	25	"	"	"	19
P - FRT 8 - 3A	"	Rc 3/8	58	"	33	27	"	"	"	22
P - FRT 10 - 1A	10 × 8	Rc 1/8	60	35.5	35.5	24.5	8	8	23	21
P - FRT 10 - 2A	"	Rc 1/4	62	"	"	26.5	"	"	"	"
P - FRT 10 - 3A	"	Rc 3/8	64	"	36	28.5	"	"	"	22
P - FRT 10 - 4A	"	Rc 1/2	66	"	38.5	30.5	"	"	"	27
P - FRT 12 - 2A	12 × 10	Rc 1/4	70	41.5	41.5	28.5	10	10	28	25
P - FRT 12 - 3A	"	Rc 3/8	72	"	"	30.5	"	"	"	"
P - FRT 12 - 4A	"	Rc 1/2	74	"	42.5	32.5	"	"	"	27
P - FRT 19 - 3A	19 × 15.8	Rc 3/8	87.5	53	53	34.8	16	14.4	38	33.5
P - FRT 19 - 4A	"	Rc 1/2	89.5	"	"	36.8	"	16	"	"
P - FRT 19 - 6A	"	Rc 3/4	93.5	"	"	40.8	"	"	"	"
P - FRT 25 - 4A	25 × 22	Rc 1/2	106	64.5	64.5	41.5	22	17.9	47.5	43
P - FRT 25 - 6A	"	Rc 3/4	110	"	"	45.5	"	22	"	"
P - FRT 25 - 8A	"	Rc 1	112	"	"	47.5	"	"	"	"
Inch tube type										Dimension:mm
※ P - FRT W1 - N1A	1/8" × 0.086"	NPT 1/8"	46	23.5	23.5	22.5	2.1	6	12	17
※ P - FRT W1 - N2A	"	NPT 1/4"	50	24.5	24.5	25.5	"	8	"	19
P - FRT W2 - N1A	1/4" × 5/32"	NPT 1/8"	48	26.5	27.5	21.5	4	4	16	17
P - FRT W2 - N2A	"	NPT 1/4"	50	"	28.5	23.5	"	"	"	19
P - FRT W2 - N3A	"	NPT 3/8"	52	"	30	25.5	"	"	"	22
P - FRT W3 - N1A	3/8" × 1/4"	NPT 1/8"	60	35.5	35.5	24.5	8	8	23	21
P - FRT W3 - N2A	"	NPT 1/4"	62	"	"	26.5	"	"	"	"
P - FRT W3 - N3A	"	NPT 3/8"	64	"	36	28.5	"	"	"	22
P - FRT W3 - N4A	"	NPT 1/2"	66	"	38.5	30.5	"	"	"	27
P - FRT W4 - N2A	1/2" × 3/8"	NPT 1/4"	70	41.5	41.5	28.5	10	10	28	25
P - FRT W4 - N3A	"	NPT 3/8"	72	"	"	30.5	"	"	"	"
P - FRT W4 - N4A	"	NPT 1/2"	74	"	42.5	32.5	"	"	"	27
P - FRT W6 - N3A	3/4" × 5/8"	NPT 3/8"	87.5	53	53	34.8	16	14.4	38	33.5
P - FRT W6 - N4A	"	NPT 1/2"	89.5	"	"	36.8	"	16	"	"
P - FRT W6 - N6A	"	NPT 3/4"	93.5	"	"	40.8	"	"	"	"
P - FRT W8 - N4A	1" × 7/8"	NPT 1/2"	106	64.5	64.5	41.5	22	17.9	47.5	43
P - FRT W8 - N6A	"	NPT 3/4"	110	"	"	45.5	"	22	"	"
P - FRT W8 - N8A	"	NPT 1"	112	"	"	47.5	"	"	"	"

- ・ミリチューブタイプでNPTネジ、インチチューブタイプでRcネジも製作可能ですのでお問合せ下さい。
- ・全ての寸法は参考値です。
- ・Wは本体2面幅を示します。
- ・※印の製品No. については、4頁に掲載の「※一部小口径品について」を参照下さい。
- ・Special items are available.
- ・All dimensions are for reference only.
- ・"W" means width of surface distance.
- ・※mark items : Please refer to page 4.