

Platform Bracket




Material: Heat-resistant ABS
RoHS 10

SZ-100 (Off-white)
SZ-100D (Dark Gray)
SZ-100S (Silver paint)

Compatible products
LS7

Mounting dimensions
(Unit: mm)

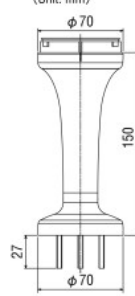

Pole Bracket



Material: PC
RoHS 10

NE-001D

Compatible products
NE-A / NE-IL

Corresponding pole
POLE22-AN (excluding NE-IL)
POLE22-AT (excluding NE-IL)
POLE-A21

Multi-mount Bracket



Material: PC

SZ-130

Compatible products
LS7

RoHS 10

Partition Mounting Bracket



Material: SECC

NH-PST

Compatible products
NH-FB

RoHS 10

Desktop Platform



SZW-060W

Compatible products
LA6-50TNWB-PCE,
LA6-5AWJWB-RYGBC

RoHS 10

SZW-002W

Compatible products
LR4-02WJ, LR5-0□W□,
LR6-02WJ, LR6-1LWM, LR6-USB
WDB, PWS

RoHS 10

Rack Mounting Bracket



Material: SECC

NBM-ANG

Compatible products
NBM

RoHS 10

Ceiling Mounting Bracket



Material: SPCE

SZW-101

Compatible products
SKH/SF10/SL10

RoHS 10



Material: ABS


RF-002

Compatible products
RFV,RFT

*It cannot be used in a place exposed to water.

RoHS 10

Mounting dimensions
(Unit: mm)

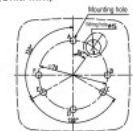

Rubber Gasket



Material: Silicon

SZW-102

Compatible products
SKS / SF08 / SL08
3-point bolt foot mounting type

RoHS 10



Material: Silicon

SZW-103

Compatible products
SKH/SF10/SL10
3-point bolt foot mounting type

RoHS 10

Serial Cable



WDX-SC01
Approximately 3 m long.

Compatible products
WDB

RoHS 10

WD System Setup Kit



WDX-4LRB

Compatible products
WDT-4LR-Z2

RoHS 10



WDX-5LRB

Compatible products
WDT-5LR-Z2

RoHS 10



WDX-6LRB

Compatible products
WDT-6LR-Z2

RoHS 10

WD System Setup Software



WDS-WIN01

Compatible products
WDR-Z2-PRO / WDR-Z2

* Free version is limited to changing the transmitter and receiver settings. Data collection only available with paid license.

Tint Film



RoHS 10

NHL-TF

Compatible products
NHL-FV2 / NHL-FB2

NHP-TF

Compatible products
NHP-FV2 / NHP-FB2 / PHE-3FB3

Universal AC Adapter



RoHS 10

ADP-001

Compatible products
NH / NBM-D88N / PHE-3FB3
PHC-D08 / WDR-LE-Z2
WDX-5LRB / WDX-6LRB
WDR-LE-Z2-PRO(-L)

Compatible countries
Japan, Europe, U.S., China, Korea, Taiwan, Thailand, Indonesia, Canada, Philippines, Vietnam