

Wall Mount Signal Tower

# WME-D

- W70 x D 80.2
- CE
- RoHS 10
- UL
- IP54
- Indoor Use
- Upright Mounting
- Ambient Temperature -10°C~+55°C
- Red, Amber, Green, Blue, White
- Continuous On
- Change Number of Tiers
- 60 Flashes per Minute
- 93dB
- 2 Sounds




## Model Number Configuration

# WME-502DFB-RYGBC

- ①
- ②
- ③
- ④


① Number of Tiers 1 = 1 tier 2 = 2 tiers 3 = 3 tiers	② Rated Voltage Q2 = 24V DC M2 = 100-240 V AC	③ Flashing / Buzzer Blank = No flashing, no buzzer FB = With flashing and buzzer	④ Luminous Color R = Red B = Blue Y = Amber C = White G = Green (Top to bottom)
---	---	--	--

## Dimensions (mm)

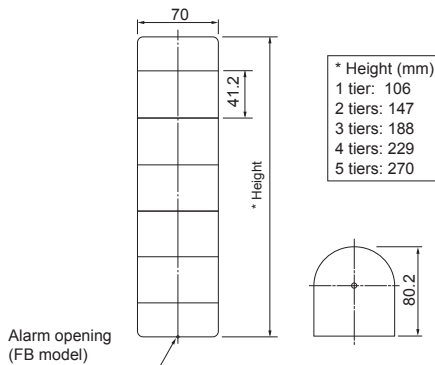

* Height (mm)
1 tier: 106
2 tiers: 147
3 tiers: 188
4 tiers: 229
5 tiers: 270

## Installation Dimensional Drawings

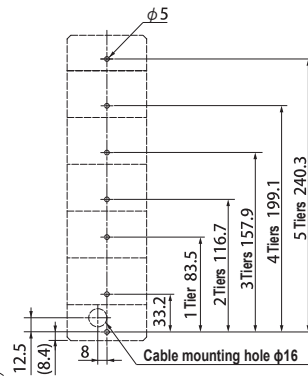

	Nominal Cross-sectional Area	Wire Type	Wire Length
Power Supply Wire	0.2mm <sup>2</sup>	UL1061	1100
Signal Wire	0.2mm <sup>2</sup>	UL1061	1100

	Nominal Cross-sectional Area	Wire Type	Wire Length
Power Supply Wire	0.8mm <sup>2</sup>	UL1015	1100
Signal Wire	0.2mm <sup>2</sup>	UL1061	1100

- \* To maintain IP54 for FB model, install the unit with the alarm opening pointing down.
- \* A special metal fitting for each tier model is included

## Specification

Supported Transistor	NPN / PNP
Alarm Sound	2 intermittent sounds. 1 (pipipi), 2 (peee, peee, peee)
Volume Control	Not adjustable