


# ST56L

## Ø56mm LED Steady/Flashing Tower Lights

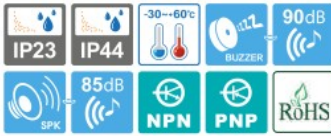

ST56L series

Built-in buzzer output holes formed on the housing of the product.



### Substitute model numbers for discontinued model

Built-in signal sound type, ST56L-WS, ST56L-WM, ST56L-WA are substituted for old model number ST56WL.

All specifications such as diameter and functions are all the same.

### Mounting Bracket

Standard	LB18	LW18	QZ18
Steel	Steel	PC	PC
SZ18	QL18	SL18	QLA18
Al	PC	Al	PC

※ Please refer to page 34-39 for detailed dimensions.

## ST56L Ø56mm Pole Mount, LED Steady/Flashing

Model number	Layer	Voltage	Current	Certificates	Weight	Color
ST56L ST56L-BZ ST56L-WS ST56L-WM ST56L-WA ST56LF ST56LF-BZ ST56LF-WS ST56LF-WM ST56LF-WA	1	AC/DC12V	0.120A	CE DC24V only UL DC24V only (buzzer type)	0.44kg	● R-Red
		AC/DC24V	0.080A		0.44kg	
		AC110V	0.048A		0.60kg	
		AC220V	0.024A		0.60kg	
	2	AC/DC12V	0.240A		0.52kg	● R-Red ● G-Green
		AC/DC24V	0.160A		0.52kg	
		AC110V	0.057A		0.68kg	
	3	AC/DC12V	0.360A		0.60kg	● R-Red ● A-Amber ● G-Green
		AC/DC24V	0.240A		0.60kg	
		AC110V	0.066A		0.76kg	
	4	AC/DC12V	0.480A		0.68kg	● R-Red ● A-Amber ● G-Green ● B-Blue
		AC/DC24V	0.320A		0.68kg	
		AC110V	0.075A		0.84kg	
	5	AC/DC12V	0.600A		0.77kg	● R-Red ● A-Amber ● G-Green ● B-Blue ● W-White
		AC/DC24V	0.400A		0.77kg	
AC110V		0.082A	0.93kg			
		AC220V	0.041A	0.93kg		

- ST56L Steady
- ST56L-BZ Built-in buzzer, Steady
- ST56L-WS Built-in 5 Warning sounds, Steady
- ST56L-WM Built-in 5 Melodies, Steady
- ST56L-WA Built-in 5 Alarms, Steady
- ST56LF Steady/ flashing
- ST56LF-BZ Built-in buzzer, Steady/ flashing
- ST56LF-WS Built-in 5 Warning sounds, Steady/ flashing
- ST56LF-WM Built-in 5 Melodies, Steady/ flashing
- ST56LF-WA Built-in 5 Alarms, Steady/ flashing

※ Please refer to page 24 for detailed information about selectable sound patterns.

### Signal/ Audible Line Current(per each layer)

Voltage	AC/DC12V	AC/DC24V	AC110V	AC220V
Signal line current	0.120A	0.080A	0.048A	0.024A
Audible line current	0.016A	0.031A	0.027A	0.030A

### Customization

- 2 buzzer sound types : Both prolonged (beep, beep) and staccato (beep, beep, beep) buzzer output available
- AC type each layer power provided(same wiring DC steady)
- DC24V voltage UL listed product
- Customized pole length available

### Ordering Specification

<b>ST56L</b>	-	<b>3</b>	-	<b>220</b>	-	<b>RAG</b>	-	<b>LW18</b>
[Model number]		[Layer]		[Voltage]		[Color]		[Mounting bracket]
<ul style="list-style-type: none"> <li>• ST56L</li> <li>• ST56L-BZ</li> <li>• ST56L-WS</li> <li>• ST56L-WM</li> <li>• ST56L-WA</li> <li>• ST56LF</li> <li>• ST56LF-BZ</li> <li>• ST56LF-WS</li> <li>• ST56LF-WM</li> <li>• ST56LF-WA</li> </ul>		<ul style="list-style-type: none"> <li>• 1-1Layer</li> <li>• 2-2Layers</li> <li>• 3-3Layers</li> <li>• 4-4Layers</li> <li>• 5-5Layers</li> </ul>		<ul style="list-style-type: none"> <li>• 12-DC12V</li> <li>• 24-DC24V</li> <li>• 110-AC110V</li> <li>• 220-AC220V</li> </ul>		<ul style="list-style-type: none"> <li>● R-Red</li> <li>● A-Amber</li> <li>● G-Green</li> <li>● B-Blue</li> <li>● W-White</li> </ul>		<ul style="list-style-type: none"> <li>• None</li> <li>• -Standard</li> <li>• Bracket</li> <li>• -LB18</li> <li>• -LW18</li> <li>• -QZ18</li> <li>• -SZ18</li> <li>• -QL18</li> <li>• -SL18</li> <li>• -QLA18</li> </ul>