


サイズ


ナット

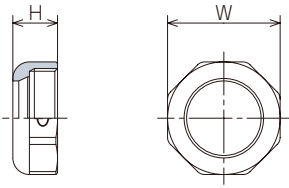

サイズ (Su)	H	W
13	12	29
20	14	34
25	15	43
30	16	49
40	18	59
50	20	68
60	24	82

エルボ


L

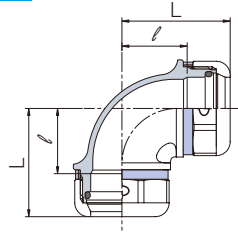

サイズ (Su)	L	ℓ
13	36	23
20	39	24.5
25	47	31.5
30	53	35
40	61	39
50	67	42.5
60	76	46

45°エルボ


45°L

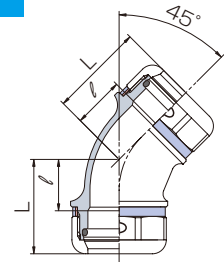

サイズ (Su)	L	ℓ
13	32	19
20	34	19.5
25	35	19.5
30	37	19
40	42	20
50	47	22.5
60	61	31

ソケット


S

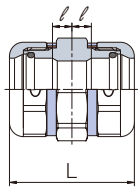

サイズ (Su)	L	ℓ
13	41	7.5
20	45	8
25	46	7.5
30	52	8
40	56	6
50	62	6.5
60	70	5

径違いソケット


RS

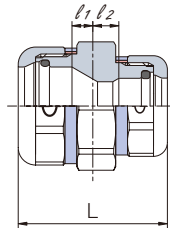

サイズ (Su)	L	ℓ ₁	ℓ ₂
20 × 13	43	7.5	8
25 × 13	44	7.5	8
25 × 20	45	7.5	7.5
30 × 13	47	7	9
30 × 20	49	7.5	9
30 × 25	50	7.5	9
40 × 13	51	6	10
40 × 20	52	6	9.5
40 × 25	53	6	9.5
40 × 30	54	6	8
50 × 20	55	5	10.5
50 × 25	56	5.5	10.5
50 × 30	57	5.5	9
50 × 40	59	5.5	7
60 × 20	62	4.5	13
60 × 25	63	4.5	13
60 × 30	64	4.5	11.5
60 × 40	66	4.5	9.5
60 × 50	67	4.5	8

径違いチーズ


RT

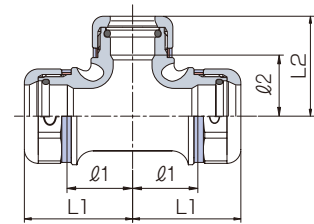

サイズ (Su)	L ₁	L ₂	ℓ ₁	ℓ ₂
20 × 13	39	36	24.5	23
25 × 13	47	42	31.5	29
25 × 20	47	46	31.5	31.5
30 × 13	53	46	35	33
30 × 20	53	48	35	33.5
30 × 25	53	47	35	31.5
40 × 13	61	51	39	38
40 × 20	61	53	39	38.5
40 × 25	61	54	39	38.5
40 × 30	61	53	39	35
50 × 13	67	55	42.5	42
50 × 20	67	57	42.5	42.5
50 × 25	67	58	42.5	42.5
50 × 30	67	61	42.5	43
50 × 40	67	66	42.5	44
60 × 20	76	64	46	49.5
60 × 25	76	66	46	50.5
60 × 30	76	68	46	50
60 × 40	76	70	46	48
60 × 50	76	72	46	47.5

チーズ

T

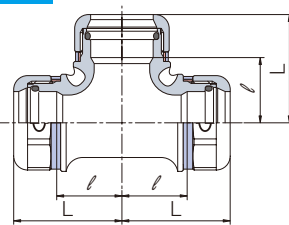

サイズ (Su)	L	ℓ
13	36	23
20	39	24.5
25	47	31.5
30	53	35
40	61	39
50	67	42.5
60	76	46

※ねじ種類 R = 管用テーパおねじ
Rc = 管用テーパめねじ
Rp = テーパおねじ用平行めねじ