


丸ワッシャー ISO



W0000000	W0010000	W0020000	W0110000	W0120000	W0130000	W0090000
鉄	黄銅	ステンレス	SUS 316	SUS 316L	SUS 310S	チタン

特長

●相手材が木材の場合、外径の大きい木材用丸ワッシャーを使用することで陥没を防ぎます。

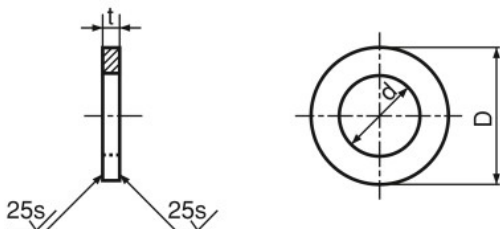

種類	小形丸・みがき丸				みがき丸		
	d		t		D		
	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差	
1	1.1	+0.15 0	0.3	±0.04	—	—	
1.2	1.3		0.3				
(1.4)	1.5		0.3				
1.6	1.7		0.3				
(1.7)	1.8		0.3				
2	2.2	+0.2 0	0.3	±0.05	5	0 -0.3	
(2.2)	2.4		0.5		6.5	0 -0.35	
(2.3)	2.5		0.5		6.5		
2.5	2.7		0.5		6.5		
(2.6)	2.8		0.5		6.5		
3	3.2		0.5		7		
(3.5)	3.7		0.5		9		
4	4.3		0.8		9		
(4.5)	4.8		0.8		±0.1		10
5	5.3		1		10		
6	6.4	+0.25 0	1.6	±0.15	12.5		0
8	8.4		1.6		17	-0.4	
10	10.5	+0.3 0	2	±0.2	21	0 -0.5	
12	13		2.5		±0.25		24
(14)	15		2.5				28
16	17		3		30		
(18)	19	+0.35 0	3	±0.3	34	0 -0.6	
20	21		3		37		
(22)	23		3		39		
24	25		4		44		
(27)	28		4		±0.4		50
30	31	+0.4 0	4	±0.5	56	0 -0.8	
(33)	34		5		60		
36	37		5		66		
(39)	40		6		±0.6		72
42	43		7		78		
(45)	46		7		85		
48	50		8		92		
(52)	54	+0.5 0	8	±0.7	98	0 -1	
56	58		9		105		
(60)	62		9		110		
64	66		9		115		
(68)	70		10		120		
72	74	+0.55	10	±1	125	0 -1.2	
(76)	78		10		135		
80	82		12		140		