


六角穴付止めねじ 平先



- 材質 ステンレス A2
- 表面処理 パシベート
- 規格 ANSI B18.3

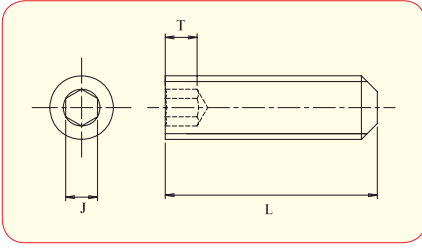

単位:インチ

呼び	#0	#1	#2	#3	#4	#5	#6	#8	#10	1/4	5/16	3/8	7/16	1/2	5/8	3/4	1
T 穴深さ	0.050	0.060	0.060	0.070	0.070	0.080	0.080	0.090	0.100	0.125	0.156	0.188	0.219	0.250	0.312	0.375	0.562
J 2面幅	0.028	0.028	0.035	0.050	0.050	1/16	1/16	5/64	3/32	1/8	5/32	3/16	7/32	1/4	5/16	3/8	9/16


サイズ		製品コード	標準 梱包
ねじの呼び	L		
#4-40	1/8	IN15.00440.010	100
	3/16	IN15.00440.015	100
	1/4	IN15.00440.020	100
#6-32	1/8	IN15.00632.010	100
	3/16	IN15.00632.015	100
	1/4	IN15.00632.020	100
	5/16	IN15.00632.025	100
#8-32	3/8	IN15.00632.030	100
	1/8	IN15.00832.010	100
	3/16	IN15.00832.015	100
#8-32	1/4	IN15.00832.020	100
	5/16	IN15.00832.025	100
	3/8	IN15.00832.030	100

サイズ		製品コード	標準 梱包
ねじの呼び	L		
#10-24	3/16	IN15.01024.015	100
	1/4	IN15.01024.020	100
	5/16	IN15.01024.025	100
	3/8	IN15.01024.030	100
#10-32	1/2	IN15.01024.040	100
	3/16	IN15.01032.015	100
	1/4	IN15.01032.020	100
	5/16	IN15.01032.025	100
#10-32	3/8	IN15.01032.030	100
	1/2	IN15.01032.040	100
	1/4	IN15.02020.020	100
	5/16	IN15.02020.025	100
1/4-20	3/8	IN15.02020.030	100
	1/2	IN15.02020.040	100
	5/8	IN15.02020.050	100
	3/4	IN15.02020.060	100
1	IN15.02020.100	100	

サイズ		製品コード	標準 梱包
ねじの呼び	L		
5/16-18	5/16	IN15.02518.025	100
	3/8	IN15.02518.030	100
	1/2	IN15.02518.040	100
	5/8	IN15.02518.050	100
	3/4	IN15.02518.060	100
3/8-16	1	IN15.02518.100	100
	3/8	IN15.03016.030	100
	1/2	IN15.03016.040	100
	5/8	IN15.03016.050	100
3/8-16	3/4	IN15.03016.060	100
	1	IN15.03016.100	100
3/8-24	7/8	IN15.03024.070	100

1本から販売致します。

すり割り付止めねじ くぼみ先

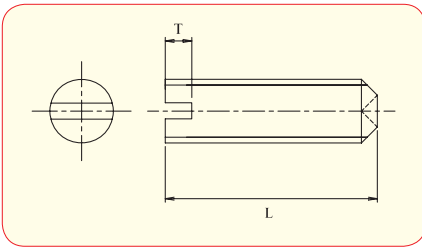

- 材質 ステンレス A2
- 表面処理 パシベート
- 規格 ASEM B18.6.2



単位:インチ

呼び	#0	#1	#2	#3	#4	#5	#6	#8	#10	1/4	5/16	3/8	7/16	1/2	5/8	3/4	1
T 穴深さ	0.050	0.060	0.060	0.070	0.070	0.080	0.080	0.090	0.100	0.125	0.156	0.188	0.219	0.250	0.312	0.375	0.562
J 2面幅	0.028	0.028	0.035	0.050	0.050	1/16	1/16	5/64	3/32	1/8	5/32	3/16	7/32	1/4	5/16	3/8	9/16

サイズ		製品コード	標準 梱包
ねじの呼び	L		
#4-40	1/8	IN16.00440.010	100
	3/16	IN16.00440.015	100
#6-32	1/8	IN16.00632.010	100
	3/16	IN16.00632.015	100
	1/4	IN16.00632.020	100
	5/16	IN16.00632.025	100
#6-32	3/8	IN16.00632.030	100
	1/8	IN16.00832.010	100
	3/16	IN16.00832.015	100
#8-32	1/4	IN16.00832.020	100
	5/16	IN16.00832.025	100
	3/8	IN16.00832.030	100
	7/16	IN16.00832.035	100
	1/2	IN16.00832.040	100
	5/8	IN16.00832.050	100
	3/4	IN16.00832.060	100

サイズ		製品コード	標準 梱包
ねじの呼び	L		
#10-24	3/16	IN16.01024.015	100
	1/4	IN16.01024.020	100
	5/16	IN16.01024.025	100
	3/8	IN16.01024.030	100
#10-24	1/2	IN16.01024.040	100
	1/8	IN16.01032.010	100
	3/16	IN16.01032.015	100
	1/4	IN16.01032.020	100
#10-32	5/16	IN16.01032.025	100
	3/8	IN16.01032.030	100
	1/2	IN16.01032.040	100
	5/8	IN16.01032.050	100
#10-32	3/4	IN16.01032.060	100
	1/4	IN16.02020.020	100
	5/16	IN16.02020.025	100
	3/8	IN16.02020.030	100
1/4-20	1/2	IN16.02020.040	100

サイズ		製品コード	標準 梱包
ねじの呼び	L		
1/4-20	5/8	IN16.02020.050	100
	3/4	IN16.02020.060	100
	1	IN16.02020.100	100
1/4-28	1/4	IN16.02028.020	100
	5/16	IN16.02028.025	100
1/4-28	1/2	IN16.02028.040	100
	5/16	IN16.02518.025	100
	3/8	IN16.02518.030	100
5/16-18	1/2	IN16.02518.040	100
	5/8	IN16.02518.050	100
	1	IN16.02518.100	100
3/8-16	3/8	IN16.03016.030	100
	1/2	IN16.03016.040	100
3/8-16	3/4	IN16.03016.060	100
	1/2-13	1/2	IN16.04013.040

1本から販売致します。