


# 310SLIM® 6-LOBE MACHINE SCREW STAINLESS SERIES



- Good corrosion resistance, best for thin plate fastening.
- 100pcs standard pack in stock.


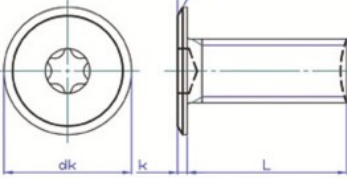


	M2	M2.6	M3	M4	M5	M6	#6	#8	#10
dk	4	6	7	8	9	12	7.5	8.0	8.5
k	0.5	0.6	0.8	0.9	1.0	1.2	0.85	0.9	0.95
t (min)	0.4	0.5	0.75	0.9	1.0	1.2	0.75	0.9	0.9
Drive	T4	T5	T6	T8	T10	T20	T6	T8	T8
A approx.	30°	30°	30°	30°	30°	30°	30°	30°	30°
<b>Min Failure Torque</b>	<b>0.4 N.m</b>	<b>0.5 N.m</b>	<b>0.95 N.m</b>	<b>2.3 N.m</b>	<b>4.0 N.m</b>	<b>10 N.m</b>	<b>0.95 N.m</b>	<b>2.3 N.m</b>	<b>2.3 N.m</b>

\* K value is reference Only for Head Painted Product.

Stainless A2 | Blacken(BK) | Bronze(B5) | Light Bronze(B3) |  
Neon Peach(NP) | Neon Lemon(NL)

Size		Part#	A2	BK	B5	B3	NP	NL	Pkg Qty
d	L								
M2	4	SH010204A2	○	○	○	○	-	-	100
	5	SH010205A2	○	○	○	○	-	-	100
	6	SH010206A2	○	○	○	○	-	-	100
	8	SH010208A2	○	○	○	○	-	-	100
	10	SH010210A2	○	○	○	○	-	-	100
	12	SH010212A2	○	○	○	○	-	-	100
M2.6	4	SH012604A2	○	○	○	○	-	-	100
	5	SH012605A2	○	○	○	○	-	-	100
	6	SH012606A2	○	○	○	○	-	-	100
	8	SH012608A2	○	○	○	○	-	-	100
	10	SH012610A2	○	○	○	○	-	-	100
	12	SH012612A2	○	○	○	○	-	-	100
M3	5	SH010305A2	○	○	○	○	-	-	100
	6	SH010306A2	○	○	○	○	-	-	100
	8	SH010308A2	○	○	○	○	-	-	100
	10	SH010310A2	○	○	○	○	-	-	100
	12	SH010312A2	○	○	○	○	-	-	100
	16	SH010316A2	○	○	○	○	-	-	100
M4	6	SH010406A2	○	○	○	○	○	○	100
	8	SH010408A2	○	○	○	○	○	○	100
	10	SH010410A2	○	○	○	○	○	○	100
	12	SH010412A2	○	○	○	○	○	○	100
	16	SH010416A2	○	○	○	○	○	○	100
	20	SH010420A2	○	○	○	○	○	○	100
	25	SH010425A2	○	○	○	○	○	○	100
M5	8	SH010508A2	○	○	○	○	○	○	100
	10	SH010510A2	○	○	○	○	○	○	100
	12	SH010512A2	○	○	○	○	○	○	100
	16	SH010516A2	○	○	○	○	○	○	100
	20	SH010520A2	○	○	○	○	○	○	100
	25	SH010525A2	○	○	○	○	○	○	100
	30	SH010530A2	○	○	○	○	○	○	100
M6	8	SH010608A2	○	○	○	○	○	○	100
	10	SH010610A2	○	○	○	○	○	○	100
	12	SH010612A2	○	○	○	○	○	○	100
	16	SH010616A2	○	○	○	○	○	○	100
	20	SH010620A2	○	○	○	○	○	○	100
	25	SH010625A2	○	○	○	○	○	○	100
	30	SH010630A2	○	○	○	○	○	○	100
	35	SH010635A2	○	○	○	○	○	○	100
40	SH010640A2	○	○	○	○	○	○	100	

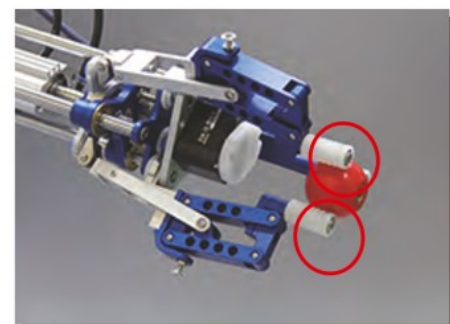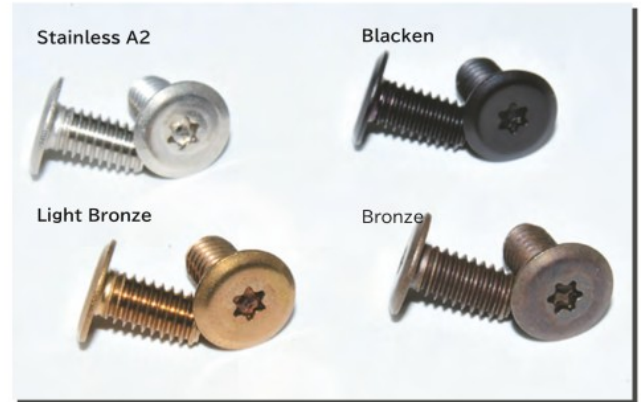

\*Head painted product is also available.