


GPLM

Bulkhead Union P

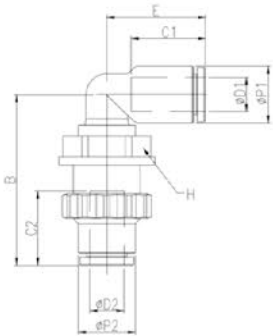

MODEL [ØD-T] Tube(Metric)–Thread(R) (mm)

MODEL	ØD1	ØD2	ØP1	ØP2	C1	C2	M	B	E	F	G	H	I	Orifice (Ømm)	W.G(g)	Q'ty/Inbox
GPLM 04	4	4	9	9	14.5	14.5	M12×1.5P	33.2	17.1	11.6	5	14	5.1	3.2	6.1	50
GPLM 06	6	6	11.2	11.2	15.5	15.5	M14×1.5P	35.3	18	13	5	17	6.6	4	9.5	50
GPLM 08	8	8	13.6	13.6	17.8	17.8	M16×1.5P	40.9	23.6	14	6	19	6.8	5.5	15.2	25
GPLM 10	10	10	16.3	16.3	19.4	19.4	M20×2.0P	45.6	25	16	6	24	8.15	9	21.9	20
GPLM 12	12	12	19.7	19.7	22.4	22.4	M24×2.0P	52.1	32.2	18	6	27	9.85	9.5	38.6	15

MODEL [ØD-T] Tube(Metric)–Thread(R) (mm)

MODEL	ØD	ØD1	ØP	B	L	C	W.G(g)	Q'ty/Inbox
GPCP 04	4	10.9	13.1	31.6	20.5	14.5	19	100
GPCP 06	6	10.9	13.1	30.3	20.5	15.5	18	100
GPCP 08	8	10.9	13.1	35.2	20.5	17.8	19	100
GPCP 10	10	10.9	13.1	41.8	20.5	19.4	31	50
GPCP 12	12	10.9	13.1	45.8	20.5	22.4	43	50
GPCP 14	14	10.9	13.1	47.8	20.5	24.4	45	25
GPCP 16	16	10.9	13.1	48.5	20.5	25	54	25

GPCP

Straight Ace Coupler Plug

