


# GPLLJ45

Plug-in Reducer Elbow

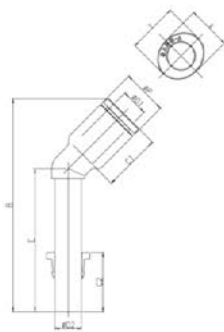

MODEL [ØD-T] Tube(Metric)–Thread(R)

(mm)


| MODEL      | ØD1 | ØD2 | ØP   | B    | C1   | C2   | E  | X    | Y    | Orifice (Ømm) | W.G(g) | Q'ty/Inbox |
|------------|-----|-----|------|------|------|------|----|------|------|---------------|--------|------------|
| GPLLJ45 04 | 4   | 4   | 9    | 45   | 14.5 | 14.5 | 30 | 8.6  | 10.8 | 2             | 1.9    | 100        |
| GPLLJ45 06 | 6   | 6   | 11.2 | 54.4 | 15.5 | 15.5 | 38 | 11   | 13   | 4             | 3.1    | 50         |
| GPLLJ45 08 | 8   | 8   | 13.6 | 64.1 | 17.8 | 17.8 | 43 | 13   | 15   | 6             | 5.1    | 50         |
| GPLLJ45 10 | 10  | 10  | 16.3 | 71.1 | 19.4 | 19.4 | 48 | 16   | 18.5 | 8             | 7.4    | 25         |
| GPLLJ45 12 | 12  | 12  | 19.7 | 83.3 | 22.4 | 22.4 | 54 | 19.5 | 22.5 | 9             | 13.9   | 25         |

MODEL [ØD-T] Tube(Metric)–Thread(R)

(mm)

# GPLGJ

Plug-in Reducer Elbow

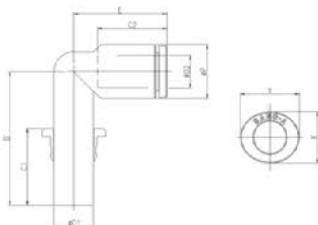

| MODEL      | ØD1 | ØD2 | ØP   | B    | C1   | C2   | E    | X   | Y    | Orifice (Ømm) | W.G(g) | Q'ty/Inbox |
|------------|-----|-----|------|------|------|------|------|-----|------|---------------|--------|------------|
| GPLGJ 0604 | 6   | 4   | 9    | 28.5 | 15.5 | 14.5 | 17.1 | 8.6 | 10.8 | 3.2           | 2.1    | 50         |
| GPLGJ 0806 | 8   | 6   | 11.2 | 30.6 | 17.8 | 15.5 | 18   | 11  | 13   | 5             | 3.2    | 50         |
| GPLGJ 1008 | 10  | 8   | 13.6 | 33.8 | 19.4 | 17.8 | 23.6 | 13  | 15   | 7             | 5.4    | 50         |
| GPLGJ 1210 | 12  | 10  | 16.3 | 38.2 | 22.4 | 19.4 | 25   | 16  | 18.5 | 9             | 8.1    | 25         |