


MODEL [ØD-T] Tube(Inch) – Thread(NPT)

MODEL	ØD	Rc	ØP	G	A	B	C	H	X	Y	Orifice (Ømm)	W.G(g)	Qty/Inbox
PCF 5/32-N01U	5/32	NPT1/8	10	11	9	25.6	16	9/16	10	12	3.5	15.3	100
PCF 5/32-N02U	5/32	NPT1/4	10	14	12	28.6	16	11/16	10	12	3.5	23.2	100
PCF 3/16-N01U	3/16	NPT1/8	10.3	11	9	26.9	17	9/16	11	13	3.5	15.1	100
PCF 3/16-N02U	3/16	NPT1/4	10.3	14	12	29.9	17	11/16	11	13	3.5	22.2	100
PCF 1/4-N01U	1/4	NPT1/8	12	10	9	26.9	17	9/16	12	14	5	15.9	100
PCF 1/4-N02U	1/4	NPT1/4	12	14	12	29.9	17	11/16	12	14	5	24.5	50
PCF 1/4-N03U	1/4	NPT3/8	12	15	13	31.2	17	7/8	12	14	5	35.3	50
PCF 5/16-N01U	5/16	NPT1/8	14	12	9	28.5	18.5	9/16	14	16	7	18.5	50
PCF 5/16-N02U	5/16	NPT1/4	14	15	12	31.3	18.5	11/16	14	16	7	27.2	50
PCF 5/16-N03U	5/16	NPT3/8	14	16	13	32.5	18.5	7/8	14	16	7	42.4	50
PCF 5/16-N04U	5/16	NPT1/2	14	19	16	35.5	18.5	7/8	14	16	7	55	25
PCF 3/8-N01U	3/8	NPT1/8	17	12	9	28.5	21	9/16	17	19	7	25.2	50
PCF 3/8-N02U	3/8	NPT1/4	17	13	12	33.9	21	11/16	17	19	9	30.8	50
PCF 3/8-N03U	3/8	NPT3/8	17	15	13	34.9	21	7/8	17	19	9	45	25
PCF 3/8-N04U	3/8	NPT1/2	17	19	16	39.5	21	7/8	17	19	9	56.7	25
PCF 1/2-N02U	1/2	NPT1/4	20.2	13	12	36.4	22.5	7/8	21	23	10	56.1	25
PCF 1/2-N03U	1/2	NPT3/8	20.2	14	13	37.4	22.5	7/8	21	23	10	57.6	25
PCF 1/2-N04U	1/2	NPT1/2	20.2	19	16	39.5	22.5	7/8	21	23	10	61.8	25

MODEL [ØD-T] Tube(Inch) – Thread(NPT)

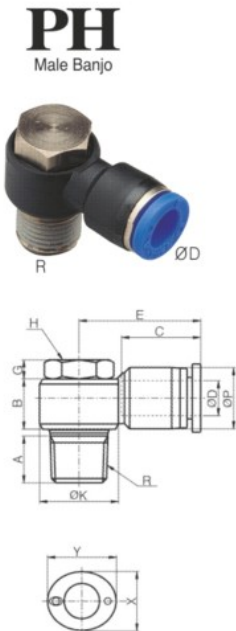

MODEL	ØD	R	ØP	A	B	C	E	H	ØK	G	X	Y	Orifice (Ømm)	W.G(g)	Qty/Inbox
PH 5/32-U10U	5/32	UNF10 * 32	10	3.5	8.9	16	19.8	13/32	10.4	3	10	12	2	7	100
PH 5/32-N01U	5/32	NPT1/8	10	8	12	16	21.5	7/16	14.4	4	10	12	2	15.8	50
PH 3/16-U10U	3/16	UNF10 * 32	11	3.5	8.9	17	22.9	13/32	10.4	3	11	13	2	8.5	100
PH 3/16-N01U	3/16	NPT1/8	11	8	12	17	23.3	7/16	14.4	4	11	13	3.5	14.7	50
PH 3/16-N02U	3/16	NPT1/4	11	11	11.8	17	25.4	9/16	18.4	4.5	11	13	3.5	27	50
PH 3/16-N03U	3/16	NPT3/8	11	12	15.5	17	28.7	9/16	22	5	11	13	3.5	28.4	50
PH 1/4-U10U	1/4	UNF10 * 32	12.4	3.5	8.9	17	23.2	13/32	10.4	3	12	14	2	7.6	100
PH 1/4-N01U	1/4	NPT1/8	12.4	8	12	17	23.6	7/16	14.4	4	12	14	4	16.4	50
PH 1/4-N02U	1/4	NPT1/4	12.4	11	11.8	17	25.7	9/16	18.4	4.5	12	14	4	28.8	50
PH 5/16-N01U	5/16	NPT1/8	14.4	8	12	18.5	25.1	7/16	14.4	4	14	16	5	17.4	50
PH 5/16-N02U	5/16	NPT1/4	14.4	11	11.8	18.5	28.3	9/16	18.4	4.5	14	16	5.5	29.9	50
PH 5/16-N03U	5/16	NPT3/8	14.4	12	15.5	18.5	28.7	3/4	22	5	14	16	6	52.4	25
PH 3/8-N02U	3/8	NPT1/4	17.6	11	11.8	21	31.6	9/16	18.4	4.5	17	19	5.5	33.2	25
PH 3/8-N03U	3/8	NPT3/8	17.6	12	15.5	21	32	3/4	22	5	17	19	8	56.4	25
PH 3/8-N04U	3/8	NPT1/2	17.6	15	17.7	21	34.3	1	28	5	17	19	8	71	20
PH 1/2-N03U	1/2	NPT3/8	21.2	12	15.5	22.5	36.3	3/4	22	5	21	23	9	58.8	25
PH 1/2-N04U	1/2	NPT1/2	21.2	15	17.7	22.5	36.3	1	28	5	21	23	9	96.2	20