


PZA31

Different Dia of Union Cross(3/1)

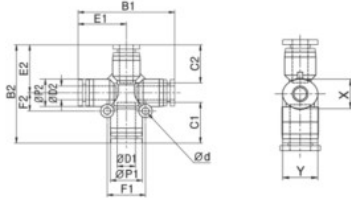

MODEL [ØD-T] Tube(Inch) – Thread(NPT)

MODEL	ØP1	ØD1	ØP2	ØD2	B1	E1	C2	B2	E2	F2	F1	Ød	C1	X	Y	Orifice (Ømm)	W.G(g)	Qty/Inbox
PZA31 5/16-1/4	14.4	5/16	12.4	1/4	43.4	21.7	18.5	17	44.4	21.7	17.2	3.2	8.2	12	14	5	14	25
PZA31 3/8-5/16	17.6	3/8	14.4	5/16	46.8	23.4	21	18.5	49.5	24.8	18.4	4.2	9.4	14	16	7	28	25
PZA31 1/2-3/8	21.2	1/2	17.6	3/8	54.2	27.1	22.5	21	56.4	28.2	21	4.2	11.5	17	19	8	42	15

PMM

Bushhead Union



MODEL [ØD-T] Tube(Inch) – Thread(NPT)

MODEL	ØD	M	A	B	C	E	H	ØP	Orifice (Ømm)	W.G(g)	Qty/Inbox
PMM 5/32	5/32	UNF1/2	18.8	32.2	16	8.6	9/16	10	3	19.2	100
PMM 3/16	3/16	UNF9/16	12.2	35.3	17	10.9	11/16	10.3	3.5	28.6	100
PMM 1/4	1/4	UNF9/16	12.9	35.7	17	9.9	11/16	12	5	25.6	50
PMM 5/16	5/16	UNF5/8	14.5	38.3	18.5	9.3	3/4	14	7	32.4	50
PMM 3/8	3/8	UNF7/8	16.4	43.3	21	10.5	1	17	8	76.6	25
PMM 1/2	1/2	UNF7/8	15.6	48	22.5	16.8	1	20.2	10	71.5	25

