



SI-2300

Disc Sander

- Vertical grip for stable and easy operation sander with 7" disc

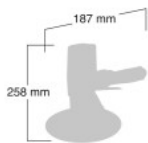

 SINGLE ACTION



Standard Accessory




Pad/Disc Size mm/(in.)	180/(7")
Spindle Size	5/8-11UNC
Free Speed r.p.m.	4,000
Out Put Watt	409
Weight kg/(lb)	2.27/(5.01)
Noise Level dBA/ (power)	82/(93)
Vibration a/k m/s ²	1.4/0.6
Max Air Consumption CFM/ (L/S)	23.4/(11.0)
Avg. Air Consumption CFM/ (L/S)	3.9/(1.8)


SI-3200A

Oscillation Sander

- Self suck system protects operator from harmful powder of paint and filler
- Oscillating mechanism tool with a triangular pad. For delicate and fine sanding work
- Special designed oscillation sander for narrow place and corner

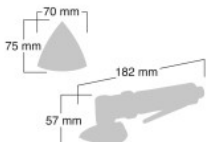

OSCILLATION

 

Standard Accessory



Pad/Disc Size mm/(in.)	△75×70
Spindle Size	M8×1.25
Oscillating Angle	2.8°
Free Speed o.p.m. ★	21,000
Out Put Watt	173
Weight kg/(lb)	0.65/(1.43)
Noise Level dBA/ (power)	83/(94)
Vibration a/k m/s ²	9.6/2.2
Max Air Consumption CFM/ (L/S)	14.4/(6.8)
Avg. Air Consumption CFM/ (L/S)	2.4/(1.1)

★o.p.m. (Oscillation Per Minutes)

SI-2322WR-LE

Wet Sanding Polisher
lever switch

- Wet sander designed for stone sanding and polishing with water
- Supplied with 14mm thread spindle
- Waterproofed mechanism ensures a long working life
- Suitable for diamond polishing and dry marble polishing
- Water exits through spindle

Standard Accessory

 


OPTION



SI-2322WR
Wet Sanding Polisher
Non lever Type

SI-2322WR-LE
SI-2322WR



Pad/Disc Size mm/(in.)	φ80
Spindle Size	M14
Free Speed r.p.m.	5,500
Out Put Watt	435
Weight kg/(lb)	1.32/(2.91)
Noise Level dBA/ (power)	88/(99)
Vibration a/k m/s ²	1.7/0.6
Max Air Consumption CFM/ (L/S)	24.0/(11.3)
Avg. Air Consumption CFM/ (L/S)	4.0/(1.9)

