


STシール

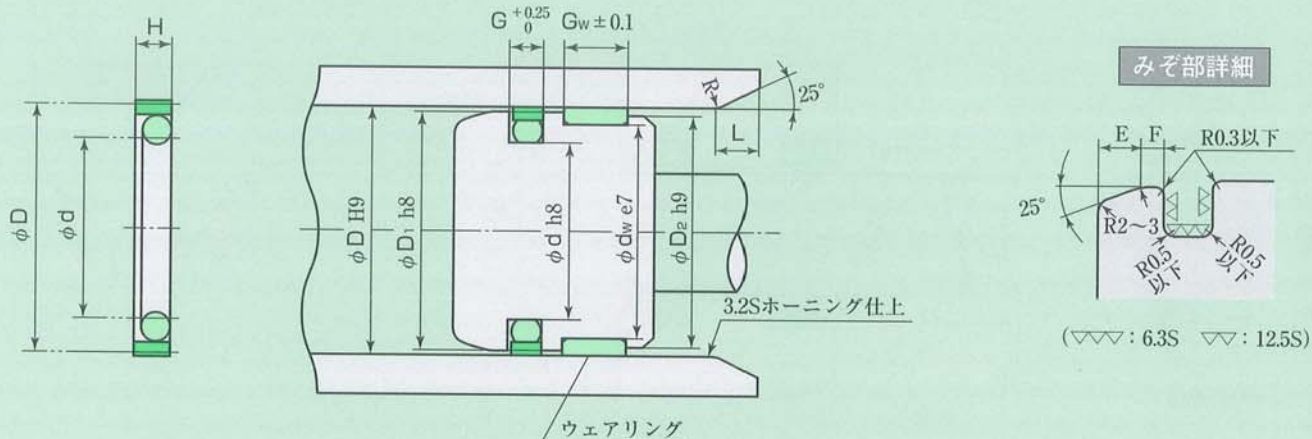

STシール寸法表

単位：mm

呼び番号 標準 (PT 111)	パッキンおよびみぞ寸法											セットリング 呼び番号
	D	d	H	G	D ₁	d _w	D ₂	G _w	E	F	L	
ST- 20	20	14	3	3.2	19.6	17	19	3	4	1	3	P- 14
ST- 25	25	19	3	3.2	24.6	22	24	3	4	1	3	P- 18
ST- 30	30	21.5	3.7	4	29.5	26	29	5	6	2	3	P- 22A
ST- 31.5	31.5	23	3.7	4	31	27.5	30	8	6	2	3	P- 22.4
ST- 32	32	23.5	3.7	4	31.5	28	30.5	8	6	2	3	P- 24
ST- 35	35	26.5	3.7	4	34.5	31	33.5	8	6	2	3	P- 26
ST- 35.5	35.5	27	3.7	4	35	31.5	34	10	6	2	3	P- 28
ST- 40	40	31.5	3.7	4	39.5	36	38.5	10	6	2	3	P- 31.5
ST- 45	45	36.5	3.7	4	44.5	41	43.5	12	6	2	3	P- 36
ST- 50	50	41.5	3.7	4	49.5	46	48.5	12	6	2	3	P- 42
ST- 53	53	44.5	3.7	4	52.4	47	51	16	6	2	3	P- 45
ST- 55	55	46.5	3.7	4	54.4	49	53	16	6	2	3	P- 46
ST- 56	56	47.5	3.7	4	55.4	50	54	16	6	2	3	P- 48
ST- 60	60	51.5	3.7	4	59.4	54	58	16	6	2	3	P- 50
ST- 63	63	49	6.2	6.5	62.4	57	61	16	7	3	4	P- 50A
ST- 65	65	51	6.2	6.5	64.4	59	63	16	7	3	4	P- 52
ST- 70	70	56	6.2	6.5	69.4	64	68	20	7	3	4	P- 56
ST- 71	71	57	6.2	6.5	70.4	65	69	20	7	3	4	P- 56
ST- 75	75	61	6.2	6.5	74.4	69	73	20	7	3	4	P- 60
ST- 80	80	66	6.2	6.5	79.4	74	78	20	7	3	4	P- 65
ST- 85	85	71	6.2	6.5	84.4	79	83	20	7	3	4	P- 70
ST- 90	90	76	6.2	6.5	89.4	84	88	25	7	3	4	P- 75
ST- 95	95	81	6.2	6.5	94.4	89	93	25	7	3	4	P- 80
ST- 100	100	86	6.2	6.5	99.4	94	98	25	7	3	4	P- 85
ST- 105	105	91	6.2	6.5	104.4	99	103	25	7	3	4	P- 90
ST- 110	110	96	6.2	6.5	109.4	104	108	30	7	3	4	P- 95
ST- 112	112	98	6.2	6.5	111.4	106	110	30	7	3	4	P- 95
ST- 115	115	101	6.2	6.5	114.4	109	113	30	7	3	4	P- 100
ST- 120	120	106	6.2	6.5	119.4	114	118	30	7	3	4	P- 105
ST- 125	125	111	6.2	6.5	124.3	119	123	30	7	3	4	P- 110

★ご注文・お問合せは、呼び番号にてご指示下さい。
★表中 呼び番号が色地のものは、在庫しております。