


PSDパッキン

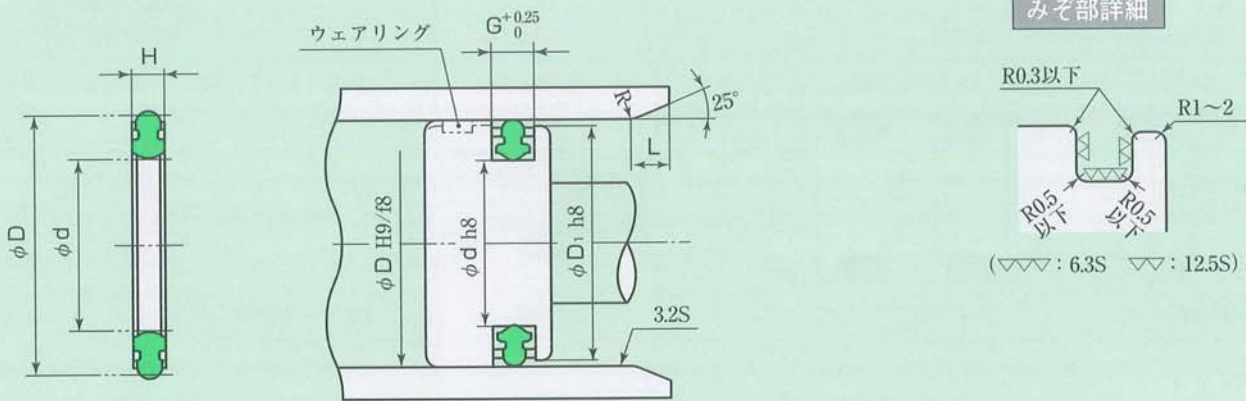

PSDパッキン寸法表

単位：mm

呼び番号		パッキンおよびみぞ寸法					
標準(RN 713)	耐熱用(RF 704)	D	d	H	G	D ₁	ℓ
PSD- 10	PSD- 10F	10	5.4	1.6	1.8	9.7	1
PSD- 12	PSD- 12F	12	7.4	1.6	1.8	11.7	1
PSD- 15	PSD- 15F	15	10.4	1.6	1.8	14.7	1
PSD- 16	PSD- 16F	16	11.4	1.6	1.8	15.7	1
PSD- 20	PSD- 20F	20	14	2.24	2.4	19.5	1.5
PSD- 25	PSD- 25F	25	17	3	3.2	24.5	2
PSD- 30	PSD- 30F	30	22	3	3.2	29.5	2
PSD- 32	PSD- 32F	32	24	3	3.2	31.5	2
PSD- 38 30 3		38	30	3	3.2	37.5	2
PSD- 40	PSD- 40F	40	32	3	3.2	39.5	2
PSD- 44 36 3		44	36	3	3.2	43.5	2
PSD- 50	PSD- 50F	50	40	3.8	4	49.5	2.5
PSD- 56 46 3.8		56	46	3.8	4	55.5	2.5
PSD- 60 50 3.8		60	50	3.8	4	59.5	2.5
PSD- 63	PSD- 63F	63	53	3.8	4	62.4	2.5
PSD- 70 55 5.6		70	55	5.6	6	69.4	3
PSD- 75 60 5.6		75	60	5.6	6	74.4	3
PSD- 80	PSD- 80F	80	65	5.6	6	79.4	3
PSD- 85 70 5.6		85	70	5.6	6	84.4	3
PSD- 90 75 5.6		90	75	5.6	6	89.4	3
PSD- 95 80 5.6		95	80	5.6	6	94.4	3
PSD- 100	PSD- 100F	100	85	5.6	6	99.4	3
PSD- 110 95 5.6		110	95	5.6	6	109.3	3
PSD- 120 105 5.6		120	105	5.6	6	119.3	3.5
PSD- 125	PSD- 125F	125	110	5.6	6	124.3	3.5
PSD- 130 115 5.6		130	115	5.6	6	129.3	3.5
PSD- 140	PSD- 140F	140	125	5.6	6	139.3	3.5
PSD- 150 135 5.6		150	135	5.6	6	149.3	3.5
PSD- 160		160	140	7.6	8	159.3	5
PSD- 175 155 7.6		175	155	7.6	8	174.3	5
PSD- 180	PSD- 180F	180	160	7.6	8	179.3	5
PSD- 200 180 7.6	PSD- 200F	200	180	7.6	8	199	5
PSD- 250 230 7.6		250	230	7.6	8	249	5
PSD- 300 280 7.6		300	280	7.6	8	299	5

★ご注文・お問合せは、呼び番号にてご指示下さい。

★表中 呼び番号が色地のものは、在庫しております。