

MINI SANDER

Pad Size 50mm(2") [DUAL ACTION]
 ● 90 degree corner type. ● Easy to grip. ● Built-in power regulator. ● 360 degree rotating rear exhaust.

SP-7201DA



Replacement parts
 ● #05202110 50 mm Pad (Velcro)

Pad Size 50mm(2") [SINGLE ACTION]
 ● 90 degree corner type. ● Easy to grip. ● Built-in power regulator. ● 360 degree rotating rear exhaust.

SP-7201G



Replacement parts
 ● #05202110 50 mm Pad (Velcro)

Pad Size 70mm(3") [DUAL ACTION]
 ● Lightweight ● Variable speed trigger. ● Built-in power regulator (4-step adjustment)

SP-1340DA



Replacement parts
 ● #05315612 70 mm Pad (Velcro)

Pad Size 70mm(3") [SINGLE ACTION]
 ● Lightweight ● Low speed and high torque. ● Variable speed trigger. ● Built-in power regulator (4-step adjustment)

SP-1331L



Replacement parts
 ● #05315612 70 mm Pad (Velcro)
 Option
 ● #40100920 Support handle grip

Pad Size 100mm(4") [SINGLE ACTION]
 ● High speed. ● Rubber grip. ● Silencer.

SP-1350



POLISHER

Pad Size 70/125mm(3"/5") [SINGLE ACTION]
 ● 90 degree corner type. ● Lower center of gravity for improved stability. ● Low speed rotation and high torque. ● Built-in power regulator. ● With bar grip. ● 360 degree rotating rear exhaust


SP-7500AH-P



Replacement parts
 ● #40100820 125 mm Pad (Velcro)
 ● #AS-111 70 mm Pad (Velcro)

Pad Size 125mm(5") [SINGLE ACTION]
 ● 120 degree corner type. ● Low speed rotation and high torque. ● Built-in power regulator. ● With anti-vibration grip.


SP-1508AH-P

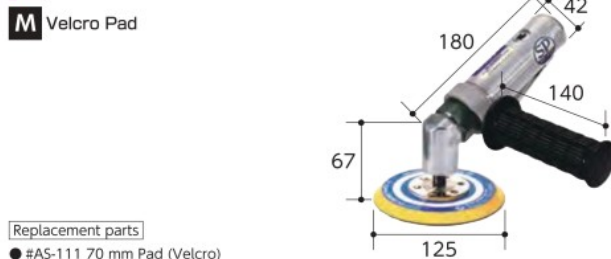

Replacement parts
 ● #AS-111 70 mm Pad (Velcro)

Pad Size 75x110mm [Window Polisher]
 ● For polishing window glass. ● Special pad. ● Built-in power regulator.

SP-3900P

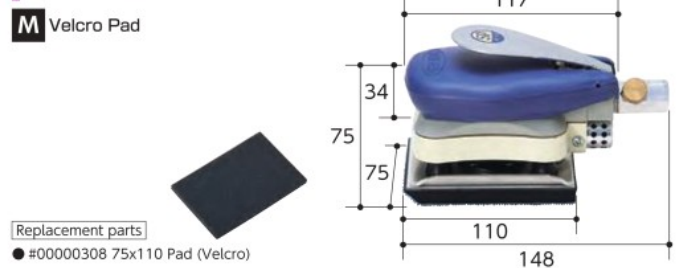

Replacement parts
 ● #00000308 75x110 Pad (Velcro)

EDP	Model No.	Pad Threads	Orbit Dia. (mm)	Install Method	Free Speed (min ⁻¹)	Overall Length (mm)	Air Consumption (m ³ /min)	Hose Coupling	Net Weight (kg)	Accessories	JAN (4545695)
370105	SP-7201DA	M6	3	Velcro	13000	158	0.3	1/4"NPT	0.6	Ø50mm Velcro Pad, Pad Fixing Bar	001483
370104	SP-7201G	M6	-	Velcro	13000	158	0.3	1/4"NPT	0.53	Ø50mm Velcro Pad, Uni top mini, Spanner (H11mm)	001476
370111	SP-1340DA	M6	2	Velcro	12000	125	0.3	1/4"NPT	0.67	Ø70mm Velcro Pad, Spanner (H17mm, H11mm), Bolt	000714
370112	SP-1331L	M6	-	Velcro	3000	145	0.3	1/4"NPT	0.7	Ø70mm Velcro Pad, Spanner (H11mm)x2, Bolt	000707
370121	SP-1350	M10x1.5	-	Disc Nut	15000	124	0.76	1/4"NPT	0.96	Ø75mm Sanding Pad, Spanner, Lock bar	001599
370116	SP-7500AH-P	5/16-24UNF	-	Velcro	1800	200	0.3	1/4"NPT	1.2	Ø70mm Velcro Pad, Ø125mm Velcro Pad, Regulator, Spanner (H17mm), Allen key (H14mm)	000974
370123	SP-1508AH-P	5/16-24UNF	-	Velcro	2500	180	0.66	1/4"NPT	1.2	Ø125 Velcro Pad, Regulator, Ø150 Urethan Pad, Ø150 Wool Pad, Comfort Grip, Spanner (H11mm)	000776
370124	SP-3900P	-	3	Velcro	9500	148	0.4	1/4"NPT	0.86	Buffing Form Pad x2	000790

Air pressure: 0.62 MPa Air hose inner dia.: 9.5 mm Rear exhaust Air connector included

FASTENING

DRILLING

SANDING

GRINDING

CUTTING

HAMMERING

BEVELER