


# レデュースングユニオン

REDUCING UNION (SFW Type)

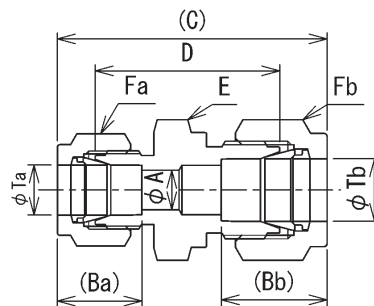

UNIT : mm

型番 TYPE NO.	チューブ 外径 TUBE O.D.		最小穴径 MIN. BORE	差込深さ DEPTH		組込長さ APPROX	本体長さ BODY	六角対辺 WIDTH ACROSS HEX		
	Ta	Tb	A	Ba	Bb	C	D	E	Fa	Fb

[ミリサイズチューブ×ミリサイズチューブ]

SFW- 6M- 8M	6	8	4.5	15.6	16.4	45.3	30	14	14	15.8
SFW- 6M-10M	6	10	4.5	15.6	17.2	46.3	31	17.4	14	19
SFW- 6M-12M	6	12	4.5	15.6	23.1	49	31	22	14	22
SFW- 8M-10M	8	10	6	16.4	17.2	46.9	31.5	17.4	15.8	19
SFW- 8M-12M	8	12	6	16.4	23.1	49.6	31.5	22	15.8	22
SFW-10M-12M	10	12	8	17.2	23.1	50.6	32.5	22	19	22

[ミリサイズチューブ×インチサイズチューブ] チューブ外径の ( ) 内はインチ表示

SFW- 6M- 4C	6	6.35(1/4")	4.5	15.6	15.6	44.2	29	14	14	14
SFW- 6M- 6C	6	9.52(3/8")	4.5	15.6	17.2	46.3	31	15.8	14	17.4
SFW- 6M- 8C	6	12.7(1/2")	4.5	15.6	23.1	49	31	22	14	22
SFW- 8M- 6C	8	9.52(3/8")	6	16.4	17.2	46.9	31.5	15.8	15.8	17.4
SFW- 8M- 8C	8	12.7(1/2")	6	16.4	23.1	49.6	31.5	22	15.8	22
SFW-10M- 8C	10	12.7(1/2")	8	17.2	23.1	50.6	32.5	22	19	22
SFW-12M- 8C	12	12.7(1/2")	10	23.1	23.1	53.3	32.5	22	22	22
SFW- 4C- 8M	6.35(1/4")	8	4.8	15.6	16.4	45.3	30	14	14	15.8
SFW- 4C-10M	6.35(1/4")	10	4.8	15.6	17.2	46.3	31	17.4	14	19
SFW- 4C-12M	6.35(1/4")	12	4.8	15.6	23.1	49	31	22	14	22
SFW- 6C-10M	9.52(3/8")	10	7.5	17.2	17.2	47.9	32.5	17.4	17.4	19
SFW- 6C-12M	9.52(3/8")	12	7.5	17.2	23.1	50.6	32.5	22	17.4	22

[インチサイズチューブ×インチサイズチューブ] チューブ外径の ( ) 内はインチ表示

SFW- 4C- 6C	6.35(1/4")	9.52(3/8")	4.8	16.4	17.2	46.3	31	15.8	14	17.4
SFW- 4C- 8C	6.35(1/4")	12.7(1/2")	4.8	16.4	23.1	49	31	22	14	22
SFW- 6C- 8C	9.52(3/8")	12.7(1/2")	7.5	17.2	23.1	50.6	32.5	22	17.4	22

◎製品改良のため、形状及び寸法は、予告無く変更することがありますので、あらかじめご了承下さい。

豆知識 ⑤ 圧力の単位の換算

MPa	Pa	Mdyn/cm <sup>2</sup>	kgf/cm <sup>2</sup>	lbf/in <sup>2</sup>	標準気圧	水銀柱
					atm	mmHg
N/mm <sup>2</sup>	N/m <sup>2</sup>	bar	at	psi		Torr
1	1×10 <sup>6</sup>	10	10.197	145.04	9.869	7500.62
1×10 <sup>-6</sup>	1	1×10 <sup>-5</sup>	1.0197×10 <sup>-3</sup>	1.4504×10 <sup>-4</sup>	9.8693×10 <sup>-6</sup>	7.50062×10 <sup>-3</sup>
0.1	100000	1	1.0197	14.504	0.9869	750.062
9.80665×10 <sup>-2</sup>	9.80665×10 <sup>1</sup>	0.980665	1	14.2233	0.9678	735.559
6.895×10 <sup>-3</sup>	6895	0.06895	0.070307	1	0.06805	51.71
0.101325	101325	1.01325	1.0332	14.696	1	760
1.3332×10 <sup>-4</sup>	133.32	0.0013332	1.35951×10 <sup>-3</sup>	0.01934	0.001316	1