


トグルクランプ用パーツ

TOGGLE CLAMP PARTS


■ボルト・ナット (ゴムヘッド付)

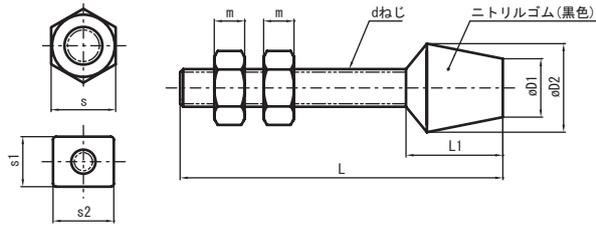

品番	d	D1	D2	L	L1	s	s1	s2	m	メーカー希望 小売価格
TNG 0422	M4 × P0.7	—	8.5	22	4	7	—	—	3	200
TNG 0425				25			8.1	9.5		
TNG 0442		10.5	13.5	42	11.5		8.2			
TNG 0442H										
TNG 0644	M6 × P1	10	15	44	14	10	—	—	5	280
TNG 0651				51						
TNG 0863	M8 × P1.25	13	18.5	63	19	13	—	—	6.5	350
TNG 0875				75						
TNG 1085	M10 × P1.5	15	23	85	24.5	17	—	—	8	570
STNG 0425	M4 × P0.7	10.5	13.5	25	11.5	7	8.2	9.5	3	580
STNG 0442				42						


※TNG0422のナットは1つです。
 ※TNG0425, TNG0442, STNG0425, STNG0442は一方のナットが四角ナットです。
 ※STNG0425, STNG0442の材質はSUS304となります。

■ボルト・ナット (スィベルヘッド付)

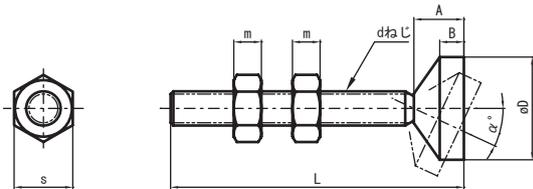

品番	d	D	L	A	B	s	m	α°	メーカー希望 小売価格
TNS 0650	M6 × P1	12	50	10	4	10	5	7	420
TNS 0865	M8 × P1.25	20	65	13	5.5	13	6.5		510
TNS 1085	M10 × P1.5		85	15	17	8	590		
TNS 12100	M12 × P1.75	25	100	20	11	19	9.6		840

■座金 (2枚1組)

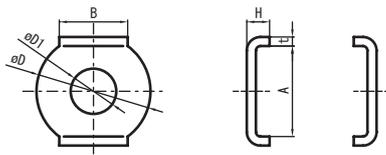

品番	D	D1	A	B	H	t	メーカー希望 小売価格
TFW 041	12	4.3	8.3	8	3.2	1	120
TFW 042	12.6	4.2	9.4	8.4	2.6		
TFW 061	14.2	6.3	11.5	7	3.9	1.5	130
TFW 062	19	6.5	14.3	12.8	3.2		
TFW 063	16.6	6.8	12.6	10.8	3.4	2	190
TFW 081	21.6		15.7	15.7	4.5		
TFW 082	22.6	8.2	17.5	15	4.7	2	260
TFW 083	25.1		19.1	16.5	5		
TFW 101	27	10.5	21.4	18.5	4.4	3	330
TFW 102	25.1		19.1	16.5	5		
TFW 103	31	10.2	22.2	22.9	8		
STFW 041	12	4.3	8.3	8	3.2	1	190
STFW 062	19	6.5	14.3	12.8	3.2	1.5	220
STFW 082	22.6	8.2	17.5	15	4.7	2	260
STFW 083	25.1		19.1	16.5	5		

※STFW041, STFW062, STFW082, STFW083の材質はSUS304となります。

