


R series

単相 複巻 タップ付

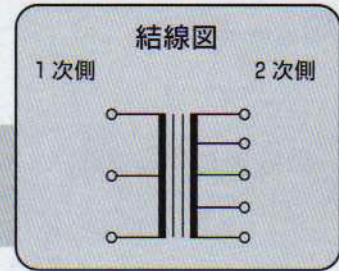


R2 200-220V-6~24V



品番	仕様			端子形状	外形寸法 (mm)				取付寸法 (mm)			端子種類	絶縁種類	重量	本体価格			
	1次電圧	2次電圧	容量		W	D	H	I	A	B	C					E	F	
○ R2-6305	220-0	6.3V 0	0.5A	BL	43	36	35	60	50			3.8×4	ラグ	A	約160g	1,200		
○ R2-631	220V		1A	BL	51	40	41	70	60			4×6	ラグ	A	約260g	1,400		
○ R2-632	200V		2A	BL	60	45	51	80	70			4×7	ラグ	A	約440g	1,800		
○ R2-633	0		3A	BL	69	50	59	91	80			4.5×6	ラグ	A	約740g	2,500		
○ R2-1203	220V 200V 0	12-10V-0	0.3A	BL	43	36	35	60	50			3.8×4	ラグ	A	約160g	1,300		
○ R2-1205		12V	0.5A	BL	51	40	41	70	60			4×6	ラグ	A	約260g	1,700		
○ R2-121		10V	1A	BL	60	45	51	84	71			4×6	ラグ	A	約440g	1,900		
○ R2-122		8V	2A	BL	69	55	59	91	80			4.5×6	ラグ	A	約770g	2,400		
○ R2-123		6V	3A	BL	79	65	67	104	92			4.5×8	ラグ	A	約1.2kg	3,600		
○ R2-125		0	5A	BL	79	75	67	104	92			4.5×7	ラグ	A	約1.6kg	4,700		
○ R2-128		12V	8A	UP	96	97	103		59	57	40	5.5×10	4	M4	A	約2.6kg	7,600	
○ R2-1210		10V	10A	UP	96	105	103		59	62	40	5.5×10	4	M4	A	約3.0kg	8,100	
○ R2-1220		6V	20A	UP	128	100	131		97	60	68	6.5×12	5	M4	A	約5.0kg	12,100	
○ R2-2005		220V 200V 0	20V	0.5A	BL	60	45	51	80	70			4×6	ラグ	A	約440g	1,800	
○ R2-201	18V		1A	BL	69	55	59	91	80			4.5×6	ラグ	A	約770g	2,500		
○ R2-202	16V		2A	BL	79	65	67	104	92			4.5×8	ラグ	A	約1.2kg	3,700		
○ R2-203	14V		3A	BL	79	75	67	104	92			4.5×7	ラグ	A	約1.6kg	4,500		
○ R2-205	0		5A	SS	96	87	82		59	62	40	5.5×10	4	ラグ	A	約2.6kg	7,300	
○ R2-2010	20V		10A	UP	108	120	118		75	73	48	6×10	4	M4	A	約4.6kg	9,900	
○ R2-2020	18V		20A	UP	128	135	131		97	80	68	5.5×12	5	M4	A	約6.5kg	15,400	
○ R2-2403	220V 200V 0		24V 20V 15V 12V 0	0.3A	BL	50	42	43	71	60			4×6	ラグ	A	約300g	1,600	
○ R2-2405				0.5A	BL	60	45	51	80	70				4×6	ラグ	A	約440g	2,500
○ R2-241				1A	BL	69	59	59	91	80				4.5×6	ラグ	A	約900g	2,800
○ R2-242		2A		BL	79	72	67	104	92				4.5×6	ラグ	A	約1.4kg	4,700	
○ R2-243		3A		BL	89	77	76	115	102				4×8	ラグ	A	約2.0kg	6,100	
○ R2-245		5A		SS	96	85	82		59	62	40	5.5×10	4	ラグ	A	約3.0kg	7,700	
○ R2-248		8A		UP	108	110	118		75	68	48	6×10	4	M4	A	約4.8kg	11,000	
○ R2-2410		10A		UP	128	100	131		97	60	68	6.5×12	5	M4	A	約5.0kg	12,700	
○ R2-2415		15A		UP	128	130	131		97	80	68	6.5×12	5	M4	A	約6.4kg	14,900	
○ R2-2420		20A		UP	146	130	145		110	72	76	6.5×12	5	M4	E	約7.2kg	17,100	

形状・寸法図

BL形 (ラグ端子板)

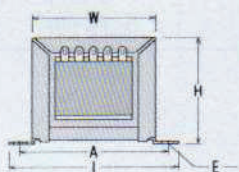

SS形 (ラグ端子板)

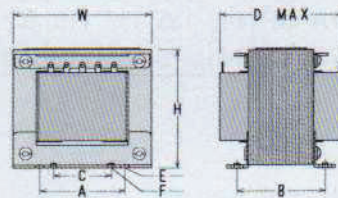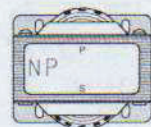

UP形 (ねじアップ式端子台)

