

Outside Caliper



Item Code	Description	Body Size (mm)	Weight (g)	JAN Code	Packing Unit	Package
73318	A 15 cm	165×100×12	62	4 960910 733183	10	
73326	B 20 cm	213×120×12	77	4 960910 733268	1	
33958	OC-6 15 cm with Spring *	175×100×20	83	4 960910 339583	1	
33959	OC-8 20 cm with Spring *	225×130×20	98	4 960910 339590		
33960	OC-10 25 cm with Spring *	285×160×25	153	4 960910 339606		
33961	OC-12 30 cm with Spring *	340×160×25	178	4 960910 339613		


*Made-to-order items

Features

- For outer dimension measurement that cannot be measured by vernier caliper

Use

- For taking readings of outer dimensions, etc.

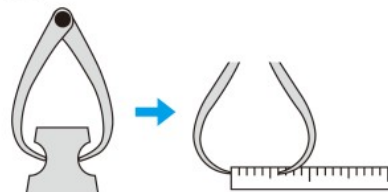

Specifications

Item Code	73318	73326
Usable Range	150 mm (radius)	200 mm (radius)
Material	Body: Carbon steel	

Item Code	33958	33959
Usable Range	150 mm (radius)	200 mm (radius)
Material	Body: Carbon steel	

Item Code	33960	33961
Usable Range	250 mm (radius)	300 mm (radius)
Material	Body: Carbon steel	

Inside Caliper



Item Code	Description	Body Size (mm)	Weight (g)	JAN Code	Packing Unit	Package
73253	A 15 cm	165×20×12	51	4 960910 732537	10	
73261	B 20 cm	210×18×12	60	4 960910 732612	1	
33954	IC-6 15 cm with Spring *	175×85×20	94	4 960910 339545	1	
33955	IC-8 20 cm with Spring *	225×100×20	123	4 960910 339552		
33956	IC-10 25 cm with Spring *	285×120×25	178	4 960910 339569		
33957	IC-12 30 cm with Spring *	340×120×25	209	4 960910 339576		


*Made-to-order items

Features

- For inner dimension measurement of a pipe or hole

Use

- For taking readings of inner dimensions, etc.

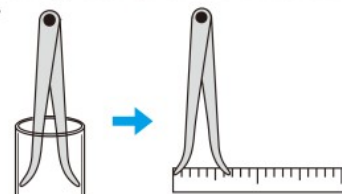


Specifications

Item Code	73253	73261
Usable Range	150 mm (radius)	200 mm (radius)
Material	Body: Carbon steel	

Item Code	33954	33955
Usable Range	150 mm (radius)	200 mm (radius)
Material	Body: Carbon steel	

Item Code	33956	33957
Usable Range	250 mm (radius)	300 mm (radius)
Material	Body: Carbon steel	

Radius Scale

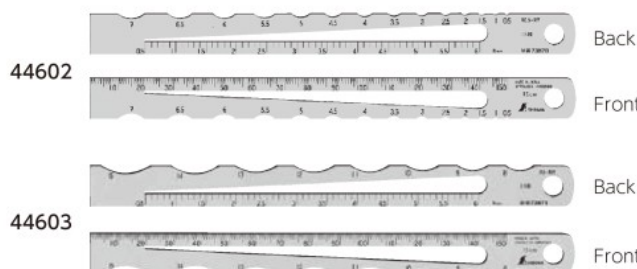

Item Code	Description	Body Size (mm)	Weight (g)	JAN Code	Packing Unit	Package
73570	A-1 R 0.5 - 7	175×15×0.5	7.5	4 960910 735705	10	
44602	A-1 R 0.5 - 7	175×15×0.5	7.5	4 960910 446021		
73571	A-2 R 8 - 15	175×15×0.5	7.5	4 960910 735712		
44603	A-2 R 8 - 15	175×15×0.5	7.5	4 960910 446038		

Features

- 1 scale can be used as a radius gauge, diameter gauge, and as a rule
- Easy to pull out and measure due to its compact size

Use

- Measurement of radius gauge, measurement of diameter and sheet thickness, and measurement of length



Specifications

Item Code	73570	44602	73571	44603
Accuracy	Radius Gauge: ±0.1 mm Diameter Gauge: ±0.05 mm Straight Rule: ±0.15 mm			
Measuring Range	Radius Gauge: R 0.5 - 7 mm Diameter Gauge: 0.5 - 6 mm Straight Rule: 150 mm		Radius Gauge: R 8 - 15 mm Diameter Gauge: 0.5 - 6 mm Straight Rule: 150 mm	
Material	Stainless steel			

Carpenter's Squares
 Stainless Steel Rules / Machine Scale
 Aluminum Rules
 Resin Rules / Bamboo Rules
 Squares / Protractors
 Vernier Calipers / Micrometers
 Tape Measures
 Surveying Products
 Scales
 Levels
 Lasers / Optical Equipment
 Inlines / Chalklines / Plumblines
 Circular Saw Guides
 Construction Tools
 Industrial Tools
 Thermometers / Hygrometers / Soldering Irons
 Outdoor Products
 Magnifying Glasses
 Drawing Tools
 Magnets