


Digital Protractor DPM-1

Set your reference points at any angle.



Features

- Two measurement modes conversion
 - ABS mode (absolute measurements)
 - Relative mode (zero-out the reading at any angle as reference points)
- A hold function to lock the reading
- Magnetic base for hands free use on ferrous metal surfaces

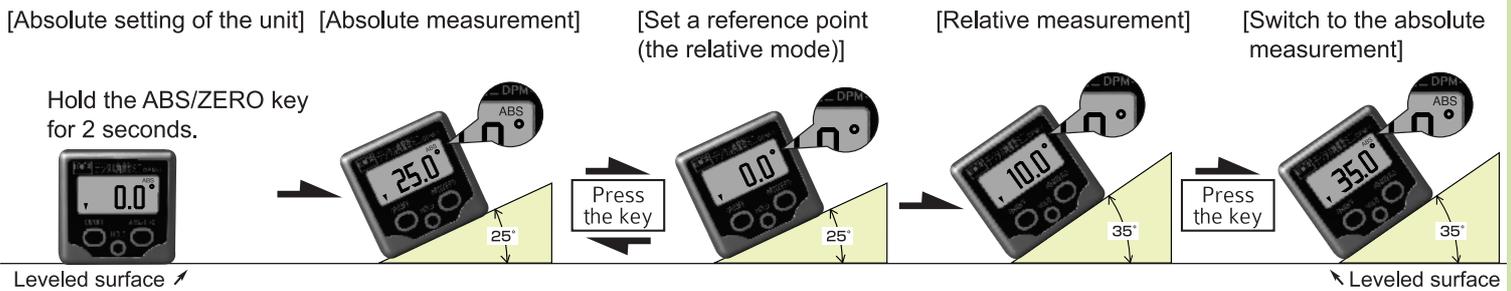

Quality assurance verification

Zero-out the reading to set a reference point

Sheet metal bending

Check bending angles

Machine tool set up

Lathe and mill alignment

Leveling

Use it as a portable level

Specifications

Size / weight	32W x 50.8H x 50.8 L (mm) / 172g
Material	aluminum alloy
Measuring range	±180°
Resolution	0.1°
Accuracy	0°, 90°, 180° = ±0.1° (±1.75mm/m) Angles not listed above = ±0.2° (±3.5mm/m)
Temperature range	0 - 45°C
Power supply	3V CR2032 lithium button cell battery
Battery life	1000 hours
Auto shut-off	After 5 minutes
Protection level	IP54

TOEI 東栄工業株式会社
Toei Industrial Co., Ltd. JAPAN
 Phone: +81-849-21-9777 FAX: +81-849-921-9776
 URL: <http://www.toei-kk.co.jp>

Distributor