


## Connect Coil

With its spring characteristic, this coil won't get kinks easily, which is appropriate for air tools.

Polyurethane product



Screw type

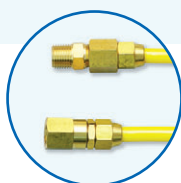

### Usege

For air-paint, air-spray, and in-factory air tools

### Features

Because of a coil form, this product will cover broader working space with fewer kinks and wears. As the edges are straightened, no hoses are necessary, and the couplers will improve the workability.

### Fluids

Air


## Sun Tech Coil

Superior in robustness in addition to high flexibility, elasticity, and wear resistance.

Polyurethane product



Coupler type

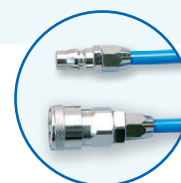

### Usege

For air-paint, air-spray, and in-factory air tools

### Features

Because of a coil form, this product will cover broader working space with fewer kinks and wears. As the edges are straightened, no hoses are necessary, and the couplers will improve the workability.

### Fluids

Air

\*This product is made in China.

Specifications: Working temperature limit: Between -40°C and + 80°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Working space (m)	Brackets of both ends	Maximum working pressure	Delivery Unit
					MPa at 20°C	
CHU-5080-3	5.0	8.0	2.0	PF 1/4 Female connector	0.7	10
CHU-5080-5	5.0	8.0	4.0	PF 1/4 Female connector	0.7	10
CHU-5080-7	5.0	8.0	6.0	PF 1/4 Female connector	0.7	10
CHU-5080-10	5.0	8.0	8.0	PF 1/4 Female connector	0.7	10
CHU-6510-3	6.5	10.0	2.0	PF 1/4 Female connector	0.7	10
CHU-6510-5	6.5	10.0	4.0	PF 1/4 Female connector	0.7	10
CHU-6510-7	6.5	10.0	6.0	PF 1/4 Female connector	0.7	10
CHU-6510-10	6.5	10.0	8.0	PF 1/4 Female connector	0.7	10
CHU-8012-3	8.0	12.0	2.0	PF 1/4 Female connector	0.7	10
CHU-8012-5	8.0	12.0	4.0	PF 1/4 Female connector	0.7	10
CHU-8012-7	8.0	12.0	6.0	PF 1/4 Female connector	0.7	10
CHU-8012-10	8.0	12.0	8.0	PF 1/4 Female connector	0.7	10

Specifications: Working temperature limit: Between -40°C and + 80°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Working space (m)	Brackets of both ends	Maximum working pressure	Delivery Unit
					MPa at 20°C	
SCH-5080-3	5.0	8.0	2.0	Two-touch coupler	0.7	10
SCH-5080-5	5.0	8.0	4.0	Two-touch coupler	0.7	10



Superior in flexibility, elasticity, and wear resistance.



Description of nominal designation **CHU** **50** **80** **—** **3** **Y**

a: material  
U= Polyurethane

b: inner diameter  
50=Φ5.0  
65=Φ6.5  
80=Φ8.0

c: outer diameter  
80=Φ8.0  
10=Φ10.0  
12=Φ12.0

d: length of straight line  
3=3.0m 7=7.0m  
5=5.0m 10=10.0m

y: color  
Y= yellow



Description of nominal designation **SCH** **50** **80** **—** **3**

b: inner diameter  
50=Φ5.0

c: outer diameter  
80=Φ8.0

d: length of straight line  
3=3.0m  
5=5.0m

