

Step Drill 2 - Combined Taps

드릴탭 2




◆ Special Feature

- Possible boring with countersinking at same time.
- Advantageous for cost, time and accuracy

◆ 제품의 특징

- 단 한번의 가공으로 나사가공을 위한 구멍작업 가능
- 비용절감, 시간절약 및 정밀도 향상에 유리

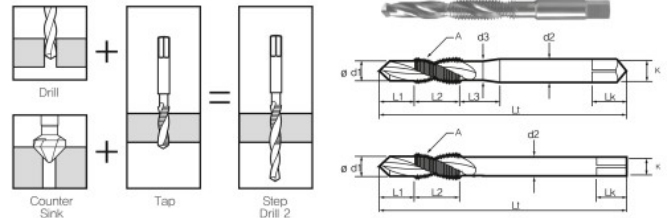


■ 드릴탭2 (M/M)

Item code 품목코드	Size 규격	D 탭외경	d1 드릴경	L1 드릴길이	L2 탭길이	d2 상크경	L 전장	KRW(원)	US \$	SET
SDC-M3	M3xp0.5	3.000	2.5	5	10	4	55	36,000	36	SDC-SET ₩ 372,000 US \$ 372
SDC-M4	M4xp0.7	4.000	3.3	6	13	5	60	42,000	42	
SDC-M5	M5xp0.8	5.000	4.2	7	15	5.5	66	42,000	42	
SDC-M6	M6xp1.0	6.000	5	8	15	6	72	48,000	48	
SDC-M8	M8xp1.25	8.000	6.8	11	16	6.2	85	54,000	54	
SDC-M10	M10xp1.5	10.000	8.5	12	18	7	90	66,000	66	
SDC-M12	M12xp1.75	12.000	10.3	15	21	8.5	106	84,000	84	

■ 드릴탭2 (INCH)

Item code 품목코드	Size 규격	D 탭외경	d1 드릴경	L1 드릴길이	L2 탭길이	d2 상크경	L 전장	KRW(원)	US \$	SET
SDC-NO6	NO.6-32UNC	3.505	2.7	5	10	5	55	42,000	42	SDC-SET ₩ 384,000 US \$ 384
SDC-NO8	NO.8-32UNC	4.166	3.4	6	13	5	60	42,000	42	
SDC-NO10	NO.10-24UNC	4.826	3.8	7	15	5.5	66	42,000	42	
SDC-NO11	NO.10-32UNC	4.826	4	7	15	5.5	66	42,000	42	
SDC-NO12	NO.12-24UNC	5.486	4.4	8	15	6	72	48,000	48	
SDC-1/4	1/4-20UNC	6.350	5.1	8	15	6	72	48,000	48	
SDC-5/16	5/16-18UNC	7.938	6.5	11	16	6.2	85	54,000	54	
SDC-3/8	3/8-16UNC	9.525	8	12	18	7	90	66,000	66	

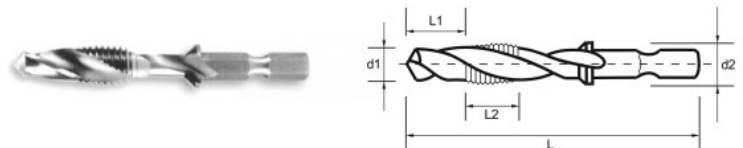

■ 육각상크 드릴탭2 (M/M)

Item code 품목코드	Size 규격	D 탭외경	d1 드릴경	L1 드릴길이	L2 탭길이	d2 상크경	L 전장	KRW(원)	US \$	SET
SDCH-M3	M3xp0.5	3.000	2.5	5	7	7	51	50,000	50.0	SDC-SET ₩ 391,000 US \$ 391
SDCH-M4	M4xp0.7	4.000	3.3	6	8.5	7	54	60,000	60.0	
SDCH-M5	M5xp0.8	5.000	4.2	7	10	7	57	60,000	60.0	
SDCH-M6	M6xp1.0	6.000	5	8	12	7	60	67,000	67.0	
SDCH-M8	M8xp1.25	8.000	6.8	11	15	9.5	68	74,000	74.0	
SDCH-M10	M10xp1.5	10.000	8.5	15	17	11.5	75	80,000	80.0	

■ 육각상크 드릴탭2 (INCH)

Item code 품목코드	Size 규격	D 탭외경	d1 드릴경	L1 드릴길이	L2 탭길이	d2 상크경	L 전장	KRW(원)	US \$	SET
SDCH-NO6	NO.6-32UNC	3.505	2.7	6	8.5	7	54	50,000	50.0	SDC-SET ₩ 518,000 US \$ 518
SDCH-NO8	NO.8-32UNC	4.166	3.4	6	8.5	7	54	60,000	60.0	
SDCH-NO10	NO.10-24UNC	4.826	3.8	7	10	7	57	60,000	60.0	
SDCH-NO11	NO.10-32UNC	4.826	4	7	10	7	57	60,000	60.0	
SDCH-NO12	NO.12-24UNC	5.486	4.4	8	12	7	60	67,000	67.0	
SDCH-1/4	1/4-20UNC	6.350	5.1	8	12	7	60	67,000	67.0	
SDCH-5/16	5/16-18UNC	7.938	6.5	11	15	9.5	68	74,000	74.0	
SDCH-3/8	3/8-16UNC	9.525	8	15	17	11.5	75	80,000	80.0	

※ Products(including TC) other than in the above table shall be produced on order-made basis

※ 상기 표 이외의 제품은(초경포함) 주문제작 합니다.



SDC 일반형(15종)	₩ 756,000	US \$ 756
SDCH 육각형(14종)	₩ 909,000	US \$ 909