 


 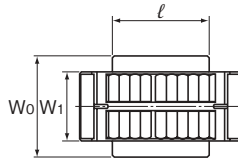


# LRB形、LRB-Z形

 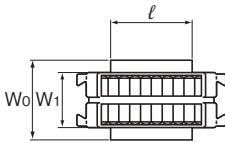


LRB形



LRB-Z形

注)LRB形にはUUシール付きタイプはありません。



LRB-Z…UU形

単位:mm

呼び形番	主要寸法							質量 g	基本動 定格荷重 C kN	基本静 定格荷重 C <sub>0</sub> kN
	W <sub>1</sub> O -0.1	長さ L	幅 W <sub>0</sub>	厚さ T	t	ℓ O -0.2	S			
LRB 1547Z	15	47	22.2	17	13	20	0.2	60	21.6	39.9
LRB 2055Z	20	55	30	18	14	30	0.2	117	38.9	84.9
LRB 2565Z	25	65	38.1	21	16	35	0.1	205	55	113
LRB 3275Z	32	75	45	22	17	45	0.1	340	88	208
LRB 4095	40	95	55	31	24	55	0.3	800	150	326
LRB 50130	50	130	76.2	43	33	78	0.3	1970	285	577

