 





## Silicone Sponge String Square



### Selection Standard

Product code	Hardness (°)	Size (A×B) (mm×mm)
SH3-30-3	20	3 x30 3m
SH3-30-10		3 x30 10m
SH3-30-50		3 x30 50m
SH5-30-3		5 x30 3m
SH5-30-10		5 x30 10m
SH5-30-50		5 x30 50m
SH10-30-3		10x30 3m
SH10-30-10		10x30 10m
SH10-30-50		10x30 50m
SH15-30-3		15x30 3m
SH15-30-10		15x30 10m
SH15-30-50		15x30 50m

## Silicone Sponge Tube

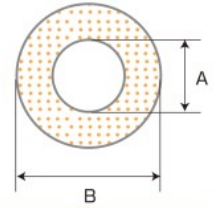

### Selection Standard

Product code	Hardness (°)	Size (A×B) (mm×mm)
ST10-20-1	20	φ10 x φ20 1m
ST10-25-1		φ10 x φ25 1m
ST15-25-1		φ15 x φ25 1m
ST20-30-1		φ20 x φ30 1m
ST25-45-1		φ25 x φ45 1m
ST10-20-3		φ10 x φ20 3m
ST10-25-3		φ10 x φ25 3m
ST15-25-3		φ15 x φ25 3m
ST20-30-3		φ20 x φ30 3m
ST25-45-3		φ25 x φ45 3m


◆With double-sided tape release paper



### Selection Standard

Product code	Hardness (°)	Size (A×B) (mm×mm)
SHP3-30-1	20	3 x30 1m
SHP5-30-1		5 x30 1m
SHP10-30-1		10 x30 1m
SHP15-30-1		15 x30 1m

## Silicone Sponge Square Tube

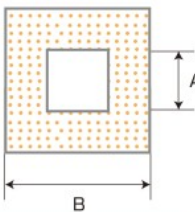

### Selection Standard

Product code	Hardness (°)	Size (A×B) (mm×mm)
SK6-10-3	20	6x10 3m
SK6-10-10		6x10 10m
SK6-10-50		6x10 50m
SK12-20-3		12x20 3m
SK12-20-10		12x20 10m
SK12-20-50		12x20 50m

## Other lineup (Custom-made product)

Product code	Hardness (°)	Size (A×B) (mm×mm)
ST5 - 15 - 50	20	φ 5 x φ15
ST5 - 20 - 50		φ 5 x φ20
ST10 - 20 - 50		φ10 x φ20
ST10 - 25 - 30		φ10 x φ25
ST10 - 30 - 30		φ10 x φ30
ST10 - 35 - 25		φ10 x φ35
ST15 - 25 - 30		φ15 x φ25
ST15 - 30 - 30		φ15 x φ30
ST15 - 35 - 25		φ15 x φ35
ST15 - 40 - 25		φ15 x φ40
ST15 - 45 - 20		φ15 x φ45
ST20 - 30 - 30		φ20 x φ30
ST20 - 35 - 25		φ20 x φ35
ST20 - 40 - 25		φ20 x φ40
ST20 - 45 - 20		φ20 x φ45
ST25 - 40 - 25		φ25 x φ40
ST25 - 45 - 20		φ25 x φ45

