
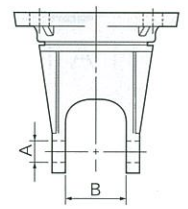
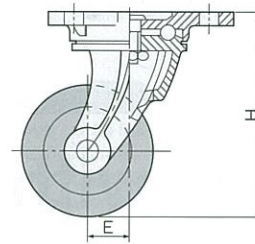


Ductile Caster for Standard Load

BR

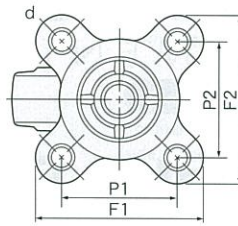

unit:mm

Wheel diameter	Type	Material	Load capacity	Total Height	Bolt hole spacing	Plate dimension	Hub length	Offset	Bolt hole diameter	Axle bore diameter
75	75BR A	Rubber (non-bearing)	70kg	112.5	65×65	91×91	40	25	11	10
	75BR B	Rubber (with bearing)								
	75BR ULB	Urethane (with bearing)	160kg							
	75BR FA	Metal (non-bearing)	140kg							
	75BR FB	Metal (with bearing)								
	75BR MCB	MC nylon (with bearing)	160kg							
100	100BR A	Rubber (non-bearing)	100kg	140	85×85	113×113	47	30	11	12
	100BR B	Rubber (with bearing)								
	100BR ULB	Urethane (with bearing)	210kg							
	100BR FA	Metal (non-bearing)	200kg							
	100BR FB	Metal (with bearing)								
	100BR MCB	MC nylon (with bearing)	210kg							
125	125BR A	Rubber (non-bearing)	180kg	168.5	100×100	128×128	52	40	11	17
	125BR B	Rubber (with bearing)								
	125BR ULB	Urethane (with bearing)	300kg							
	125BR FA	Metal (non-bearing)	360kg							
	125BR FB	Metal (with bearing)								
	125BR MCB	MC nylon (with bearing)	360kg							
150	150BR A	Rubber (non-bearing)	200kg	195	100×100	128×128	56	40	11	20
	150BR B	Rubber (with bearing)								
	150BR ULB	Urethane (with bearing)	350kg							
	150BR FA	Metal (non-bearing)	400kg							
	150BR FB	Metal (with bearing)								
	150BR MCB	MC nylon (with bearing)	400kg							
180	180BR A	Rubber (non-bearing)	240kg	225	110×110	144×144	57	45	11	20
	180BR B	Rubber (with bearing)								
	180BR ULB	Urethane (with bearing)	430kg							
	180BR FA	Metal (non-bearing)	480kg							
	180BR FB	Metal (with bearing)								
	180BR MCB	MC nylon (with bearing)	480kg							
200	200BR A	Rubber (non-bearing)	250kg	250	120×120	156×156	60	50	14	20
	200BR B	Rubber (with bearing)								
	200BR ULB	Urethane (with bearing)	500kg							
	200BR FA	Metal (non-bearing)								
	200BR FB	Urethane (with bearing)								
	200BR MCB	MC nylon (with bearing)								
230	230BR A	Rubber (non-bearing)	280kg	290	140×140	180×180	66	60	14	25
	230BR B	Rubber (with bearing)								
250	250BR A	Rubber (non-bearing)	340kg	300	140×140	180×180	66	60	14	25
	250BR B	Rubber (with bearing)								
	250BR ULB	Urethane (with bearing)	650kg							
	250BR FA	Metal (non-bearing)	680kg							
	250BR FB	Metal (with bearing)								
	250BR MCB	MC nylon (with bearing)	680kg							
300	300BR A	Rubber (non-bearing)	360kg	350	160×160	204×204	70	65	14	25
	300BR B	Rubber (with bearing)								
	300BR ULB	Urethane (with bearing)	830kg							
	300BR FB	Metal (with bearing)								
	300BR MCB	MC nylon (with bearing)								