
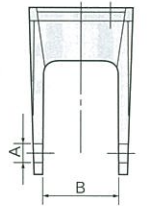
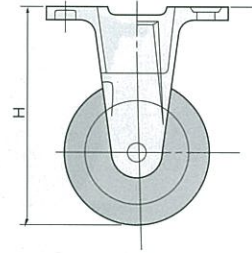


K

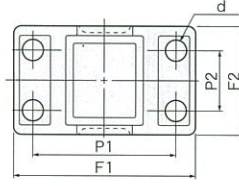

unit:mm

Wheel diameter	Type	Material	Load capacity	Total Height	Bolt hole spacing	Plate dimension	Hub length	Bolt hole diameter	Axle bore diameter
75	75K A	Rubber (non-bearing)	70kg	112.5	75 (2 holes)	95×57	40	11	10
	75K B	Rubber (with bearing)							
	75K ULB	Urethane (with bearing)	160kg						
	75K FA	Metal (non-bearing)	140kg						
	75K FB	Metal (with bearing)							
	75K MCB	MC nylon (with bearing)	160kg						
100	100K A	Rubber (non-bearing)	100kg	140	90 (2 holes)	115×61	47	11	12
	100K B	Rubber (with bearing)							
	100K ULB	Urethane (with bearing)	210kg						
	100K FA	Metal (non-bearing)	200kg						
	100K FB	Metal (with bearing)							
	100K MCB	MC nylon (with bearing)	210kg						
125	125K A	Rubber (non-bearing)	180kg	168.5	105×32	130×68	53	11	17
	125K B	Rubber (with bearing)							
	125K ULB	Urethane (with bearing)	300kg						
	125K FA	Metal (non-bearing)	360kg						
	125K FB	Metal (with bearing)							
	125K MCB	MC nylon (with bearing)	360kg						
150	150K A	Rubber (non-bearing)	200kg	195	120×45	150×73	57	11	20
	150K B	Rubber (with bearing)							
	150K ULB	Urethane (with bearing)	350kg						
	150K FA	Metal (non-bearing)	400kg						
	150K FB	Metal (with bearing)							
	150K MCB	MC nylon (with bearing)	400kg						
180	180K A	Rubber (non-bearing)	240kg	225	135×45	160×73	57	11	20
	180K B	Rubber (with bearing)							
	180K ULB	Urethane (with bearing)	430kg						
	180K FA	Metal (non-bearing)	480kg						
	180K FB	Metal (with bearing)							
	180K MCB	MC nylon (with bearing)	480kg						
200	200K A	Rubber (non-bearing)	250kg	250	150×50	180×80	61	14	20
	200K B	Rubber (with bearing)							
	200K ULB	Urethane (with bearing)	500kg						
	200K FA	Metal (non-bearing)							
	200K FB	Urethane (with bearing)							
	200K MCB	MC nylon (with bearing)	500kg						
230	230K A	Rubber (non-bearing)	280kg	290	160×60	190×88	67	14	25
	230K B	Rubber (with bearing)							
250	250K A	Rubber (non-bearing)	340kg	300	160×60	190×88	67	14	25
	250K B	Rubber (with bearing)							
	250K ULB	Urethane (with bearing)	650kg						
	250K FA	Metal (non-bearing)	680kg						
	250K FB	Metal (with bearing)							
	250K MCB	MC nylon (with bearing)	680kg						
300	300K A	Rubber (non-bearing)	360kg	350	175×60	206×92	71	14	25
	300K B	Rubber (with bearing)							
	300K ULB	Urethane (with bearing)	830kg						
	300K FB	Metal (with bearing)							
	300K MCB	MC nylon (with bearing)	830kg						