 

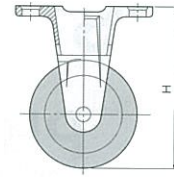


# TK

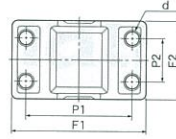

unit:mm

Wheel diameter	Type	Material	Load capacity	Total Height	Bolt hole spacing	Plate dimension	Hub length	Bolt hole diameter	Axle bore diameter
100	100×50TK B	Rubber (with bearing)	140kg	145	124×64	152×95	71	11	17
	100×65TK B		180kg		124×78	152×105	81		
	100×50TK ULB	Urethane (with bearing)	340kg		124×64	152×95	71		
125	125×50TK B	Rubber (with bearing)	180kg	178.5	140×64	170×95	71	11	25
	125×65TK B		220kg		140×78	170×105	81		
	125×50TK ULB	Urethane (with bearing)	400kg		140×64	170×95	71		
	125×50TK FB	Metal (with bearing)	400kg		140×64	170×95	71		
	125×65TK FB		470kg		140×78	170×105	81		
150	150×50TK B	Rubber (with bearing)	210kg	205	152×64	188×100	71	14	25
	150×65TK B		250kg		152×78	188×110	81		
	150×75TK B		310kg		152×86	188×125	96		
	150×50TK ULB	Urethane (with bearing)	440kg		152×64	188×100	71		
	150×65TK ULB		590kg		152×78	188×110	81		
	150×75TK ULB		720kg		152×86	188×125	96		
	150×50TK FB	Metal (with bearing)	440kg		152×64	188×100	71		
	150×65TK FB		590kg		152×78	188×110	81		
	150×75TK FB		720kg		152×86	188×125	96		
180	180×50TK B	Rubber (with bearing)	250kg	235	166×64	200×100	71	14	25
	180×65TK B		280kg		166×78	200×110	81		
	180×75TK B		350kg		166×86	200×125	96		
200	200×50TK B	Rubber (with bearing)	280kg	260	174×64	208×100	71	14	25
	200×65TK B		320kg		174×78	208×110	81		
	200×75TK B		380kg		174×86	208×125	96		
	200×90TK B		510kg		174×100	208×135	106		
	200×50TK ULB	Urethane (with bearing)	650kg		174×64	208×100	71		
	200×65TK ULB		720kg		174×78	208×110	81		
	200×75TK ULB		880kg		174×86	208×125	96		
	200×90TK ULB		1000kg		174×100	208×135	106		
	200×75TK FB	Metal (with bearing)	880kg		174×86	208×125	96		
250	250×65TK B	Rubber (with bearing)	400kg	315	184×78	220×115	81	14	30
	250×75TK B		470kg		184×86	220×130	96		
	250×90TK B		580kg		184×102	220×140	106		
	250×65TK ULB	Urethane (with bearing)	900kg		184×78	220×115	81		
	250×75TK ULB		1070kg		184×86	220×130	96		
	250×90TK ULB		1270kg		184×102	220×140	106		
	250×65TK FB	Metal (with bearing)	900kg		184×78	220×115	81		
	250×75TK FB		1070kg		184×86	220×130	96		
300	300×75TK B	Rubber (with bearing)	540kg	365	194×86	230×130	96	16	30
	300×90TK B		620kg	360	194×102	230×140	106		
	300×100TK B		900kg	360	192×151	234×192	118		
	300×75TK ULB	Urethane (with bearing)	1210kg	365	194×86	230×130	96		
	300×90TK ULB		1450kg	365	194×102	230×140	106		
	300×100TK ULB		1610kg	360	192×151	234×192	118		
	300×75TK FB		Metal (with bearing)	1210kg	365	194×86	230×130		