



Caster for Heavy Loads

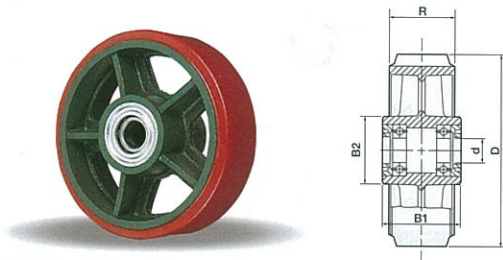

TULB Urethane (with bearing)

unit:mm

Wheel diameter	Type	Load capacity	Wheel width	Hub length	Axle hole diameter	Boss diameter	Bearing No
100	100×50TULB	340 kg	50	65	17	47	#6203
125	125×50TULB	400 kg	50	65	25	73	#6305
150	150×50TULB	440 kg	50	65	25	73	#6305
	150×65TULB	590 kg	65	76			
	150×75TULB	720 kg	75	90			
200	200×50TULB	650 kg	50	65	25	75	#6305
	200×65TULB	720 kg	65	76			
	200×75TULB	880 kg	75	90			
	200×90TULB	1000kg	89	95			
250	250×65TULB	900 kg	65	76	30	76	#6206
	250×75TULB	1070 kg	75	90			
	250×90TULB	1270 kg	90	100			
300	300×75TULB	1210 kg	75	90	30	77	#6206
	300×90TULB	1450 kg	90	100		100	#6208
	300×100TULB	1610 kg	102	114			
350	350×75TULB	1600 kg	75	90	50	78	#6210
400	400×90TULB	2000 kg	90	100	60	98	#6212
500	500×100TULB	3000 kg	100	115	90	112	#6218

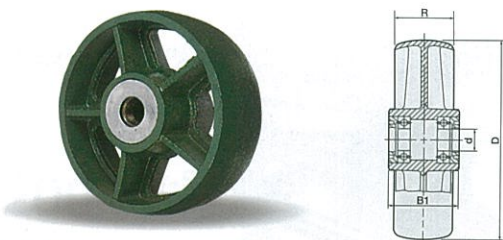

TFB Metal (with bearing)

unit:mm

Wheel diameter	Type	Load capacity	Diameter	Wheel width	Hub length	Bearing No
125	125×50	400 kg	127	50	65	#6305
	125×65	470 kg	127	65	76	
150	150×50	440 kg	150	50	65	#6305
	150×65	590 kg	150	65	76	
	150×75	720 kg	150	75	90	
200	200×75	880 kg	200	75	90	#6305
250	250×65	900 kg	250	65	76	#6206
	250×75	1070 kg	250	75	90	
300	300×75	1210 kg	300	75	90	#6206