


# CH SERIES

## CH CONTROL BOX

Technical data  
Protection class IP40

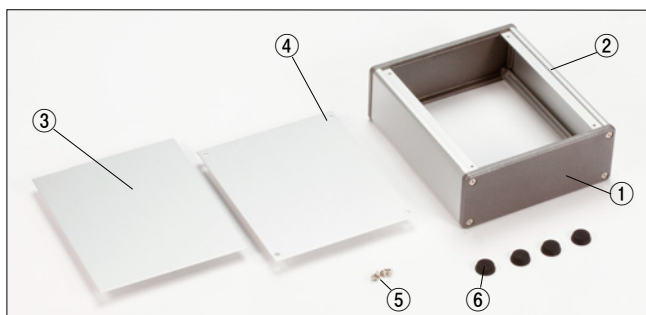

### FEATURE

- Simple design and high-strength with aluminium die-cast and aluminium extrusion.
- Both slide panel and screwed panel can be used as the front panel.

### Components

Ref. #	Part name	Pcs	Material	Color / Finish
1	Side plate	2	Die-cast aluminium	Black · Metallic gray / Powder coated
2	Frame	2	Aluminium extrusion	Silver · Black / Anodized
3	Slide panel	1	Aluminium t1.5	Black painted
			Aluminium t1.5	Silver anodized hair-line finish
4	Screwed panel	1	Aluminium t1.5	Black painted
			Aluminium t1.5	Silver anodized hair-line finish
5	Screw	1 set	Steel	Black trivalent chromate · Nickel plated
6	Rubber feet	4	Rubber	Black

### Color Type

Color code	Frame color	Side plate
BBP	Black	Black
GSP	Silver	Metallic Gray

### Part no. / Dimensions

Part no.	W	H	D	a	Weight(kg)
CH4- 7-10□□□	70	36.5	100.5	60	0.15
CH4-10-10□□□	100	36.5	100.5	90	0.20
CH4-15-10□□□	150	36.5	100.5	140	0.27
CH4-20-10□□□	200	36.5	100.5	190	0.35
CH4-25-10□□□	250	36.5	100.5	240	0.42
CH6- 8-14□□□	80	55	140	68	0.25
CH6-11-14□□□	110	55	140	98	0.31
CH6-16-14□□□	160	55	140	148	0.41
CH6-22-14□□□	220	55	140	208	0.53
CH6-29-14□□□	290	55	140	278	0.67

• Please suffix color code at the end of part number □□□ when ordering CH series.

Part no.	W	H	D	a	Weight(kg)
CH7- 9-17□□□	90	65.5	168.5	74	0.50
CH7-12-17□□□	120	65.5	168.5	104	0.58
CH7-17-17□□□	170	65.5	168.5	154	0.72
CH7-25-17□□□	250	65.5	168.5	234	0.94
CH7-33-17□□□	330	65.5	168.5	314	1.16
CH8-15-23□□□	150	75	230	134	0.74
CH8-25-23□□□	250	75	230	234	1.06
CH8-33-23□□□	330	75	230	314	1.31
CH8-43-23□□□	430	75	230	414	1.63