



# MSC·MSCL SERIES



## MSC MOUNTING PLATE FOR MS · MSN · MSY · MSR

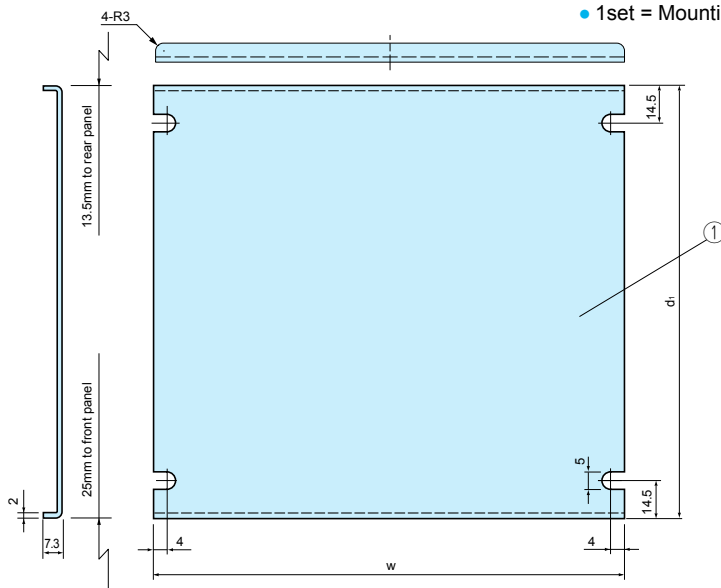

• 1set = Mounting plate + L-mounting bracket.

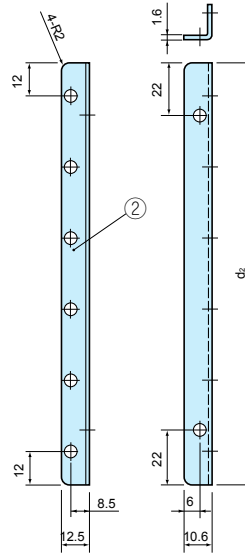

2 installation ways by changing the mounting bracket direction.

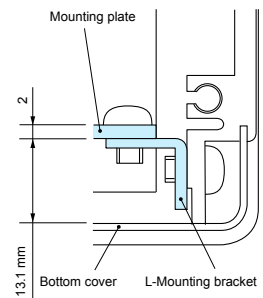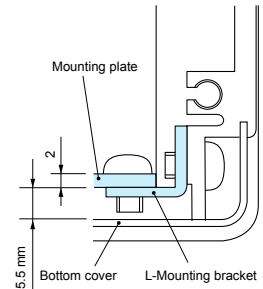

### Components

Ref. #	Part name	Pcs	Material	Color / Finish
1	Mounting plate	1	Aluminium t=2.0	Unfinished
2	L-Mounting bracket	2	Steel	Trivalent chromate
-	Screw	8	Steel M4	Trivalent chromate

• A pair of L-Mounting blackests come with MSC Mounting plate.


• CAD data is downloadable from our website.

### Part no. / Dimensions

Part no.	w	d1	d2	Case W×D	Weight(g)
MSC 16-16	130	96.5	91.5	160×160	120
16-23	130	166.5	161.5	160×230	210
16-28	130	216.5	211.5	160×280	270
21-16	180	96.5	91.5	210×160	150
21-23	180	166.5	161.5	210×230	250
21-28	180	216.5	211.5	210×280	330
21-35	180	286.5	281.5	210×350	430
26-23	230	166.5	161.5	260×230	300
26-28	230	216.5	211.5	260×280	390
26-35	230	286.5	281.5	260×350	510
32-23	290	166.5	161.5	320×230	360

Part no.	w	d1	d2	Case W×D	Weight(g)
MSC 32-28	290	216.5	211.5	320×280	460
32-35	290	286.5	281.5	320×350	600
32-45	290	386.5	381.5	320×450	810
37-23	340	166.5	161.5	370×230	410
37-28	340	216.5	211.5	370×280	520
37-35	340	286.5	281.5	370×350	680
37-45	340	386.5	381.5	370×450	910
43-23	400	166.5	161.5	430×230	460
43-28	400	216.5	211.5	430×280	590
43-35	400	286.5	281.5	430×350	770
43-45	400	386.5	381.5	430×450	1,040

## MSCL L-MOUNTING BRACKET

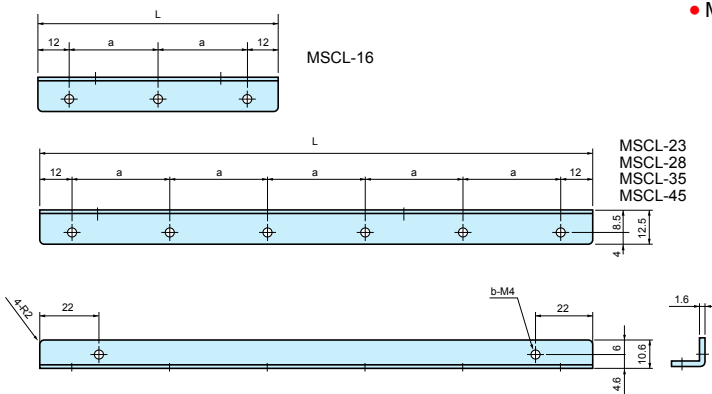

• MSCL L-mounting bracket is not necessary in case of purchasing MSC.

### Components

Part name	Material	Color / Finish
L-bracket	Steel	Trivalent chromate

### Part no. / Dimensions

1set = 2pcs

Part no.	L	a	b	Sales unit
MSCL-16	91.5	33.75	5	2
MSCL-23	161.5	27.5	8	2
MSCL-28	211.5	37.5	8	2
MSCL-35	281.5	51.5	8	2
MSCL-45	381.5	71.5	8	2